



Standard Life PS

300M 120/130V 12/1PK

Standard Life Incandescent, vacuum or gas-filled lamp has a crystal clear bulb and a completely visible filament, so the brightness of the light is not 'softened.' It imparts a sparkling radiance to larger luminaires and wall brackets with textured or satin-etched glass and cut crystal. It is the appropriate lamp for large luminaires with clear glass bowls, mounted indoors or outdoors. It is recommended in all such cases where brilliance and sparkle are more important than the avoidance of glare. These lamps are also used for indirect lighting in closed luminaires.

Product data

General information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Main Application	General Lighting (G)
Gas Filling	Gas
Rated Lifetime (Hours)	750 h

Light technical	
Luminous Flux (Max)	4625 lm
Luminous Flux (Nom)	6280 lm

Operating and electrical	
Power (Nom)	300 W
Voltage (Nom)	120-130 V


Mechanical and housing	
Bulb Finish	Clear

Cap-Base Information	Aluminium Cap
Filament Shape	CC-8 [Axial]
Bulb Shape	PS25

Product data	
Order product name	300M 120/130V 12/1PK
EAN/UPC - Product	046677133917
Order code	920140734302
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	920140734302
Net Weight (Piece)	0.001 kg

Standard Life PS

Dimensional drawing

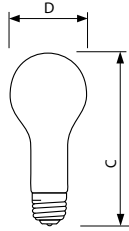

Product

300M 120/130V 12/1PK

300M 120/130V 12/1PK

