



# MR16

## 35MR16/FL36 50PK

Philips Halogen MR16 lamps provide a bright white light for accent lighting. They make it easy to optimize the look and feel of your brand, your merchandise, and the shoppers experience, with lower operating costs.


### Product data

General information	
Cap-Base	GU5.3 [ GU5.3]
Philips Code	14598
Operating Position	UNIVERSAL [ Any or Universal (U)]
ANSI Code Halogen	FMW
Nominal Lifetime (Nom)	3000 h
Rated Lifetime (Hours)	3000 h
Rated Lifetime (Years)	3 a
Light technical	
Beam Angle (Nom)	36 °
Luminous Intensity (Max)	1000 cd
Correlated Color Temperature (Nom)	3000 K
Color Rendering Index (Nom)	100
Operating and electrical	
Power (Nom)	35.0 W
Lamp Current (Nom)	3 A
Starting Time (Nom)	0.0 s
Voltage (Nom)	12 V
Controls and dimming	
Dimmable	Yes

Mechanical and housing	
Bulb Shape	MR16 [ 2inch/50mm]
Luminaire design requirements	
Bulb Temperature (Max)	250 °C
Cap-Base Temperature (Max)	350 °C
Cap-Base Temperature (Max)-DUP(do not use)	662 °F
Product data	
Order product name	35MR16/FL36 50PK
EAN/UPC - Product	046677140564
Order code	924047817126
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	50
Material Nr. (12NC)	924047817126
Net Weight (Piece)	30.000 g
ILCOS Code	HRGI-35-12-GU5.3-50/36

## MR16

### Dimensional drawing

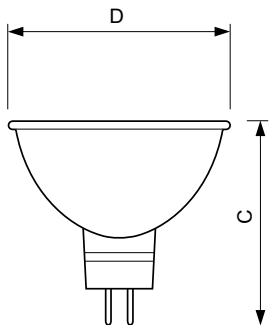

35MR16/FL36 50PK

Product	D (max)	C (max)
35MR16/FL36 50PK	51 mm	46 mm

