



Circline

FC8T9/COOL WHITE PLUS

T9 4-Pin Circular Fluorescent Lamps.


Product data

General Information	
Cap-Base	G10Q [G10q]
Life to 50% Failures (Nom)	13,000 hour(s)
Light Technical	
Color Code	33
Luminous Flux	1,050 lumen
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4100 K
Color rendering index (CRI)	62
Operating and Electrical	
Power Consumption	20.5 W
Lamp Current (Nom)	0.37 A
Voltage (Nom)	61 V
Voltage (Nom)	61 V
Controls and Dimming	
Dimmable	No

Mechanical and Housing	
Bulb Shape	C-T9 [C-T9 29 mm]
Approval and Application	
Mercury (Hg) Content (Nom)	8.0 mg
Product Data	
Order product name	FC8T9/COOL WHITE PLUS
Order code	928028403335
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	928028403335
Full product name	FC8T9/COOL WHITE PLUS
EAN/UPC - Case	50046677391169
EAN/UPC - Product/Case	046677391164

Circline

Dimensional drawing

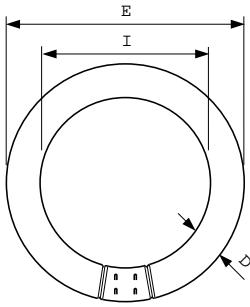

Product	D (max)	D (min)	E (min)	E (max)	I (min)	I (max)
FC8T9/COOL WHITE PLUS	31.0 mm	26.2 mm	203.2 mm	215.9 mm	149.1 mm	155.7 mm

