



T5 Standard

14W/841 Min Bipin T5 HE ALTO UNP/40

Philips T5 Fluorescent Lamps featuring ALTO® Lamp Technology offer increased energy savings and low toxicity in a slim profile.

Product data

General Information	
Cap-Base	G5 [G5]
Features	HE Alto® [High Efficiency Alto]
Light Technical	
Color Code	841 [CCT of 4100K]
Luminous Flux	1,350 lumen
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4100 K
Luminous Efficacy (rated) (Nom)	86 lm/W
Color rendering index (CRI)	82
Operating and Electrical	
Power Consumption	14.0 W
Lamp Current (Nom)	0.165 A
Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Shape	T5 [16 mm (T5)]
Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg
Product Data	
Order product name	14W/841 Min Bipin T5 HE ALTO UNP/40
Order code	927990484022
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	40
Material Nr. (12NC)	927990484022
Full product name	14W/841 Min Bipin T5 HE ALTO UNP/40
EAN/UPC - Case	50046677230802
EAN/UPC - Product/Case	046677230807



T5 Standard

Dimensional drawing

1

Product	D (max)	A (max)	B (max)	B (min)	C (max)
14W/841 Min Bipin T5 HE ALTO UNP/40	17 mm	549.0 mm	556.1 mm	553.7 mm	563.2 mm

Lifetime

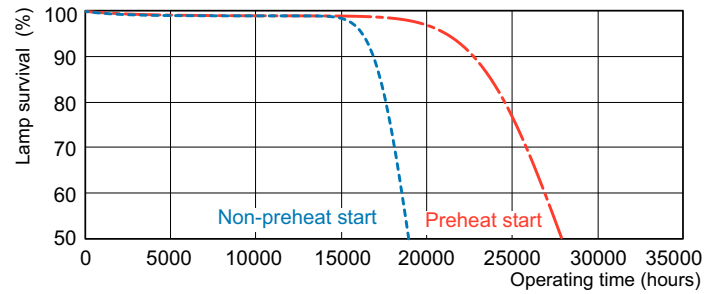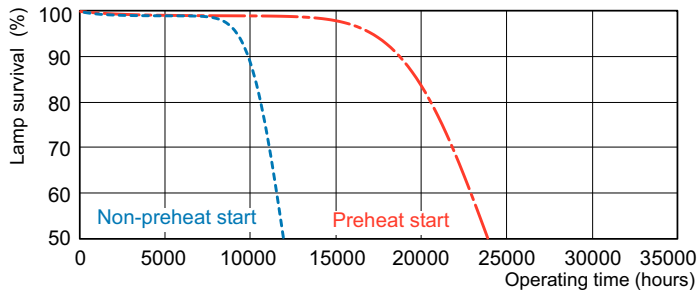

Life Expectancy Diagram - 14W/841 Min Bipin T5 HE ALTO UNP/40

Life Expectancy Diagram - 14W/841 Min Bipin T5 HE ALTO UNP/40



Lumen Maintenance Diagram - 14W/841 Min Bipin T5 HE ALTO UNP/40

T5 Standard

