



Rough / Vibration Service

50A/2P/RS 12/2 PK

Philips Family of Specialty Incandescents provide the perfect light for dramatic accents and display lighting as well as general lighting in a variety of applications. Rough Service incandescent lamps have an exceptionally strong filament for which a special filament wire is used, which makes these lamps extremely suitable for places where shocks, bumps and vibrations frequently occur. The clear version, with its completely visible filament, is a brilliant light source, whereas the inside-frosted lamp is used wherever well diffused light is required.

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Rated Lifetime (Hours)	2,000 hour(s)
Lighting Technology	Incandescent

Operating and Electrical	
Power Consumption	50 W
Voltage (Nom)	130 V
Voltage (Nom)	130 V


Mechanical and Housing	
Bulb Finish	Frosted

Bulb Shape	A19 [A 19mm]
------------	--------------

Product Data	
Order product name	50A/2P/RS 12/2 PK
Order code	925278036104
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	925278036104
Full product name	50A/2P/RS 12/2 PK
EAN/UPC - Case	50046677286892
EAN/UPC - Product/Case	046677286897

Rough / Vibration Service

Dimensional drawing

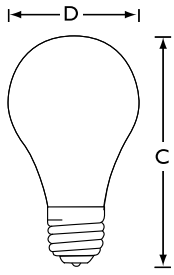

A19

Product	D	C (max)
50A/2P/RS 12/2 PK	2.375 inch	4.438 inch

