



T5 High Output

F24T5/830/HO/ALTO 40PK

Philips T5 HO lamps are environmentally-responsible, ultra-slim and have extraordinary light output and longer life.

Product data


General Information	
Cap-Base	G5 [G5]
Features	HO Alto® [High Output Alto]
Light Technical	
Color Code	830 [CCT of 3000K]
Luminous Flux	1,950 lumen
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	76 lm/W
Color rendering index (CRI)	82
Operating and Electrical	
Power Consumption	22.5 W
Lamp Current (Nom)	0.295 A
Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Shape	T5 [16 mm (T5)]
Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg
Product Data	
Order product name	F24T5/830/HO/ALTO 40PK
Order code	927992183022
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	40
Material Nr. (12NC)	927992183022
Full product name	F24T5/830/HO/ALTO 40PK
EAN/UPC - Case	50046677290196
EAN/UPC - Product/Case	046677290191


T5 High Output

Dimensional drawing

Product	D (max)	A (max)	B (max)	B (min)	C (max)
F24T5/830/HO/ALTO 40PK	17 mm	549.0 mm	556.1 mm	553.7 mm	563.2 mm


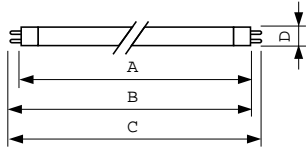


Photometric data

 

Spectral Power Distribution Colour - F24T5/830/HO/ALTO 40PK

 Lifetime

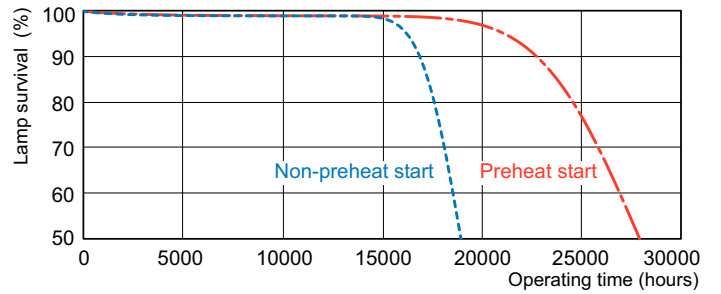


Life Expectancy Diagram - F24T5/830/HO/ALTO 40PK

Life Expectancy Diagram - F24T5/830/HO/ALTO 40PK

T5 High Output

Lifetime

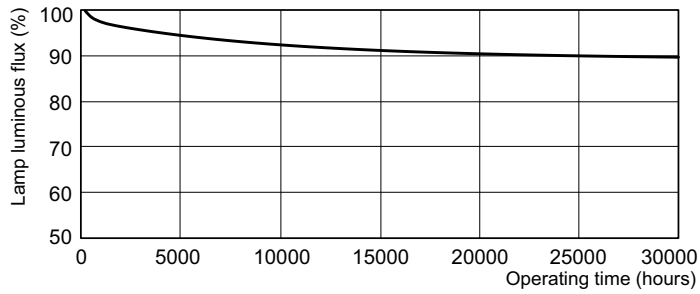

Lumen Maintenance Diagram - F24T5/830/HO/ALTO 40PK

