



# T5 High Output

## 39W/841 Min Bipin T5 HO ALTO UNP

Philips T5 HO lamps are environmentally-responsible, ultra-slim and have extraordinary light output and longer life.


### Product data

General Information	
Cap-Base	G5 [G5]
Features	HO Alto® [High Output Alto]
Light Technical	
Color Code	841 [CCT of 4100K]
Luminous Flux	3,500 lumen
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4100 K
Luminous Efficacy (rated) (Nom)	82 lm/W
Color rendering index (CRI)	82
Operating and Electrical	
Power Consumption	38.0 W
Lamp Current (Nom)	0.325 A
Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Shape	T5 [16 mm (T5)]
Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg
Product Data	
Order product name	39W/841 Min Bipin T5 HO ALTO UNP
Order code	927992684022
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	40
Material Nr. (12NC)	927992684022
Full product name	39W/841 Min Bipin T5 HO ALTO UNP
EAN/UPC - Case	50046677290257
EAN/UPC - Product/Case	046677290252


# T5 High Output

## Dimensional drawing

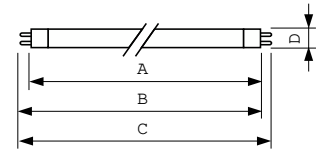


Product	D (max)	A (max)	B (max)	B (min)	C (max)
39W/841 Min Bipin T5 HO ALTO UNP	17 mm	849.0 mm	856.1 mm	853.7 mm	863.2 mm

## Photometric data

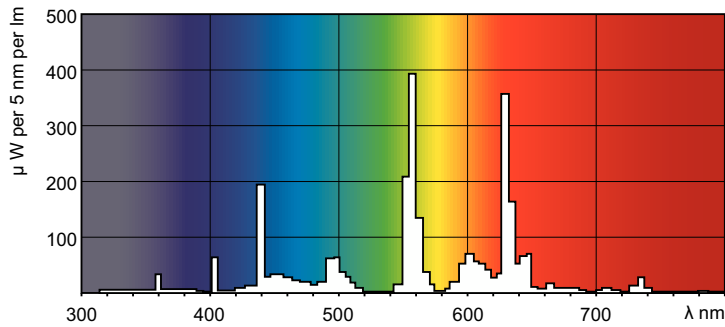


Spectral Power Distribution Colour - 39W/841 Min Bipin T5 HO ALTO UNP

## Lifetime

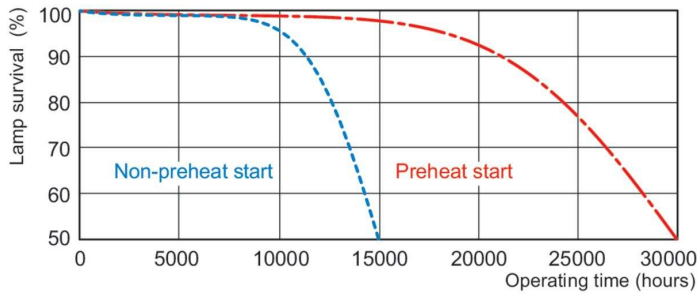


Life Expectancy Diagram - 39W/841 Min Bipin T5 HO ALTO UNP

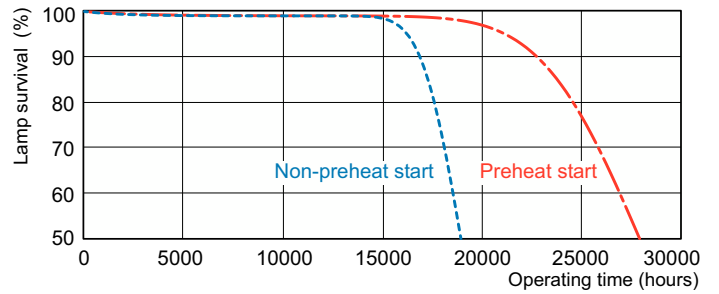

Life Expectancy Diagram - 39W/841 Min Bipin T5 HO ALTO UNP

## T5 High Output

### Lifetime

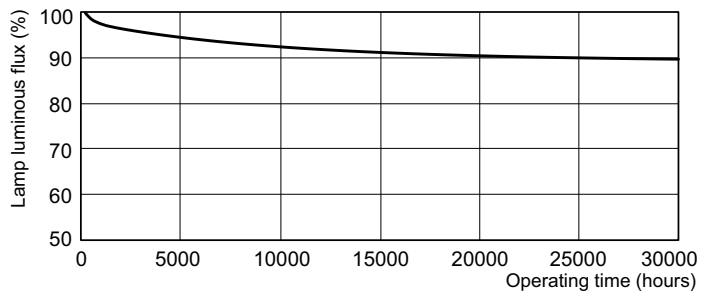

Lumen Maintenance Diagram - 39W/841 Min Bipin T5 HO ALTO UNP

