



T5 High Output

54W/835 Min Bipin T5 HO ALTO UNP

Philips T5 HO lamps are environmentally-responsible, ultra-slim and have extraordinary light output and longer life.


Product data

General Information	
Cap-Base	G5 [G5]
Features	HO Alto® [High Output Alto]
Light Technical	
Color Code	835 [CCT of 3500K]
Luminous Flux	5,000 lumen
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3500 K
Luminous Efficacy (rated) (Nom)	83 lm/W
Color rendering index (CRI)	82
Operating and Electrical	
Power Consumption	54.1 W
Lamp Current (Nom)	0.455 A
Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Shape	T5 [16 mm (T5)]
Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg
Product Data	
Order product name	54W/835 Min Bipin T5 HO ALTO UNP
Order code	927993183522
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	40
Material Nr. (12NC)	927993183522
Full product name	54W/835 Min Bipin T5 HO ALTO UNP
EAN/UPC - Case	50046677290288
EAN/UPC - Product/Case	046677290283


T5 High Output

Dimensional drawing

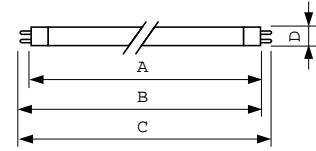



Product	D (max)	A (max)	B (max)	B (min)	C (max)
54W/835 Min Bipin T5 HO ALTO UNP	17 mm	1,149.0 mm	1,156.1 mm	1,153.7 mm	1,163.2 mm

Photometric data

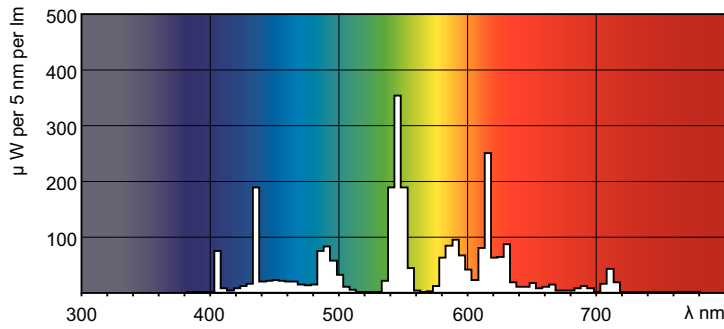

Spectral Power Distribution Colour - 54W/835 Min Bipin T5 HO ALTO UNP

 Lifetime

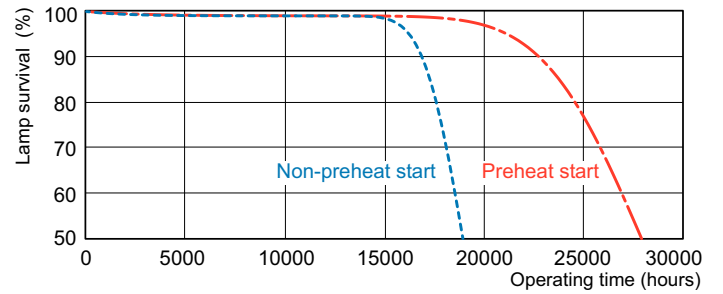


Life Expectancy Diagram - 54W/835 Min Bipin T5 HO ALTO UNP

Life Expectancy Diagram - 54W/835 Min Bipin T5 HO ALTO UNP

T5 High Output

Lifetime

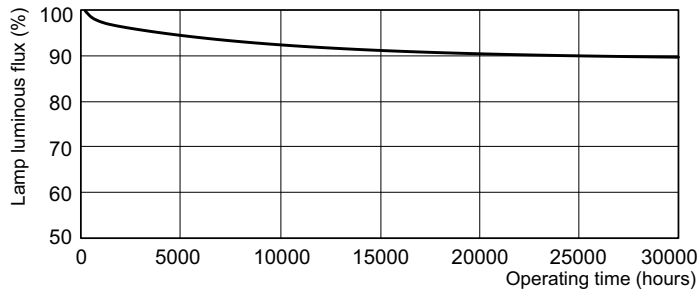

Lumen Maintenance Diagram - 54W/835 Min Bipin T5 HO ALTO UNP

