



PL-L Energy Advantage

PL-L 40W/835/XEW/4P/IS 25W 1CT/25

Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.


Product data

| General Information | |
|------------------------------------|--------------------|
| Cap-Base | 2G11 [2G11] |
| Light Technical | |
| Color Code | 835 [CCT of 3500K] |
| Luminous Flux | 2,600 lumen |
| Color Designation | White (WH) |
| Correlated Color Temperature (Nom) | 3500 K |
| Color rendering index (CRI) | 82 |
| Operating and Electrical | |
| Power Consumption | 29.0 W |
| Lamp Current (Nom) | 0.285 A |
| Controls and Dimming | |
| Dimmable | Yes |

| Approval and Application | |
|---------------------------------|-----------------------------------|
| Mercury (Hg) Content (Nom) | 1.4 mg |
| Product Data | |
| Order product name | PL-L 40W/835/XEW/4P/IS 25W 1CT/25 |
| Order code | 927908383521 |
| Numerator - Quantity Per Pack | 1 |
| Numerator - Packs per outer box | 25 |
| Material Nr. (12NC) | 927908383521 |
| Full product name | PL-L 40W/835/XEW/4P/IS 25W 1CT/25 |
| EAN/UPC - Case | 50046677209143 |
| EAN/UPC - Product/Case | 046677209148 |


PL-L Energy Advantage

Dimensional drawing

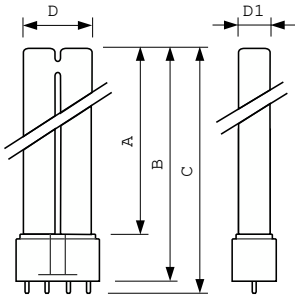

| Product | D (max) | D1 (max) | A (max) | B (max) | C (max) |
|--------------------------------------|---------|----------|----------|----------|----------|
| PL-L 40W/835/XEW/4P/IS 25W 1CT/25 | 39.0 mm | 18.0 mm | 539.2 mm | 565.0 mm | 571.6 mm |

Photometric data

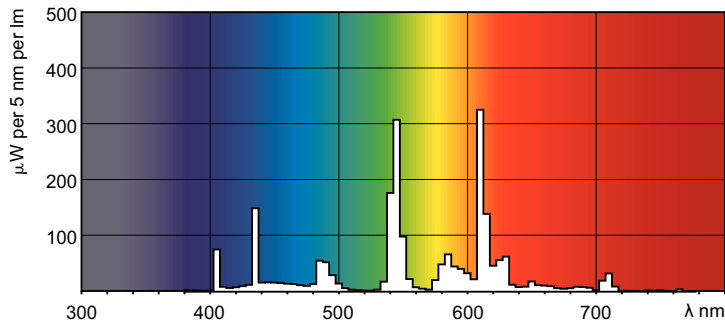

Spectral Power Distribution Colour - PL-L 40W/835/XEW/4P/IS 25W 1CT/25

