



# Reflector Infrared BR40, PAR38

## 250BR40 IR/1 120V 4/1

Philips Family of Specialty Incandescents provide the perfect light for dramatic accents and display lighting as well as general lighting in a variety of applications. Philips Infrared lamps are suited for heating and drying in industrial and commercial applications. These incandescent, gas-filled infrared heat lamps come up to full temperature almost immediately, eliminating costly warm-up time. Highly efficient heat generators that produce a minimum of light rays and a high amount of infrared radiation. The BR40 lamp provides a built-in reflector for radiant energy control.

### Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Nominal lifetime	5,000 hour(s)
Rated Lifetime (Hours)	5,000 hour(s)
Lighting Technology	Incandescent

Operating and Electrical	
Power Consumption	250 W
Wattage Equivalent	250 W
Voltage (Nom)	120 V
Voltage (Nom)	120 V

Controls and Dimming	
Dimmable	No


Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Hard Glass
Bulb Shape	BR40

Product Data	
Order product name	250BR40 IR/1 120V 4/1
Order code	925255136308
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	925255136308
Full product name	250BR40 IR/1 120V 4/1
EAN/UPC - Case	50046677203837
EAN/UPC - Product/Case	046677203832

## Reflector Infrared BR40,PAR38

### Dimensional drawing

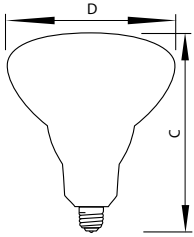

Product	D	C (max)
250BR40 IR/1 120V 4/1	125 mm	174.6 mm

