



PL-C Cluster 4-Pin Base

PL-C 26W/830/4P/ALTO 10PK


Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

Product data

General Information		Approval and Application	
Cap-Base	G24Q-3 [G24q-3]	Mercury (Hg) Content (Nom)	1.4 mg
		Energy Consumption kWh/1000 h	29 kWh
Light Technical		Product Data	
Color Code	830 [CCT of 3000K]	Order product name	PL-C 26W/830/4P/ALTO 10PK
Luminous Flux	1,800 lumen	Order code	927907383030
Color Designation	Warm White (WW)	Numerator - Quantity Per Pack	1
Correlated Color Temperature (Nom)	3000 K	Numerator - Packs per outer box	10
Luminous Efficacy (rated) (Nom)	67 lm/W	Material Nr. (12NC)	927907383030
Color rendering index (CRI)	82	Full product name	PL-C 26W/830/4P/ALTO 10PK
Operating and Electrical		EAN/UPC - Case	60046677240259
Power Consumption	26.0 W	EAN/UPC - Product/Case	046677240257
Lamp Current (Nom)	0.335 A		
Controls and Dimming			
Dimmable	Yes		


PL-C Cluster 4-Pin Base

Dimensional drawing

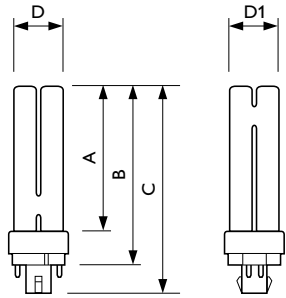


Product	D (max)	D1 (max)	A (max)	B (max)	C (max)
PL-C 26W/830/4P/ALTO 10PK	27.1 mm	27.1 mm	130.5 mm	149.0 mm	163.9 mm

 Photometric data




Spectral Power Distribution Colour - PL-C 26W/830/4P/ALTO 10PK

Lifetime

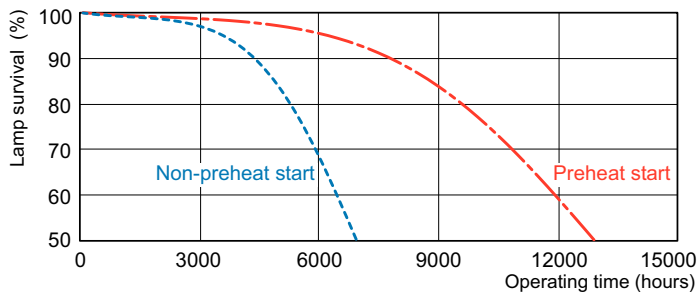

Life Expectancy Diagram - PL-C 26W/830/4P/ALTO 10PK

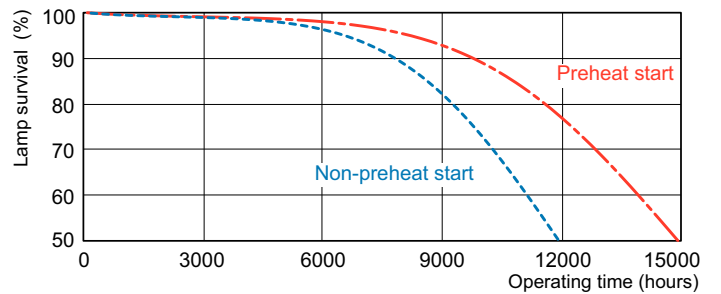

Life Expectancy Diagram - PL-C 26W/830/4P/ALTO 10PK

PL-C Cluster 4-Pin Base

Lifetime



Lumen Maintenance Diagram - PL-C 26W/830/4P/ALTO 10PK

