



PL-C/T

8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1

Philips PLED 4-pin & 2-pin lamps are an affordable LED solution to replace compact fluorescent lamps. The product provides a natural lighting effect for use in many lighting applications, and provides instant energy savings, making them an environmentally-friendly solution. Available as replacements for 13W, 26W and 32W compact fluorescent lamps.

Product data

General Information	
Cap-Base	G24q [G24q]
Nominal lifetime	50,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
EU RoHS compliant	Yes
Light Technical	
Color Code	840 [CCT of 4000K]
Beam Angle (Nom)	120 degree(s)
Luminous Flux	950 lumen
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4000 K
Luminous Efficacy (rated) (Nom)	111.00 lm/W
Color Consistency	<6
Color rendering index (CRI)	82
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Line Frequency	20000-100000 Hz
Input Frequency	20000-100000 Hz
Power Consumption	8.5 W

Lamp Current (Max)	550 mA
Lamp Current (Min)	150 mA
Wattage Equivalent	26 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.9
Voltage (Nom)	120 V
UL Type	UL Type A
Temperature	
Ambient temperature range	-20 °C to 45 °C
T-Case Maximum (Nom)	60 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Product Length	200 mm
Bulb Shape	PL-C;PL-T

PL-C/T

Approval and Application

Energy Saving Product	Yes
Approval Marks	RoHS compliance UL certificate KEMA Keur certificate DLC compliance
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	DLC Standard

Application Conditions


can it be used in closed luminaires	Yes
-------------------------------------	-----

Product Data

Order product name	8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1
--------------------	---



Order code	929001388304
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001388304
Full product name	8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1
EAN/UPC - Case	50046677472783
EAN/UPC - Product/Case	046677458393

Dimensional drawing

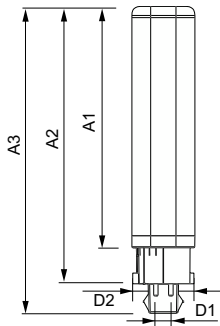

Product	D1	D2	A1	A2	A3
8.5PL-C/T/COR/ 26H-840/IF9/P/4P/DIM 10/1	24.3 mm	28.4 mm	128.3 mm	147.5 mm	163.1 mm

Photometric data

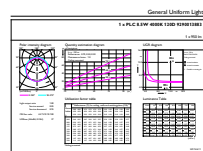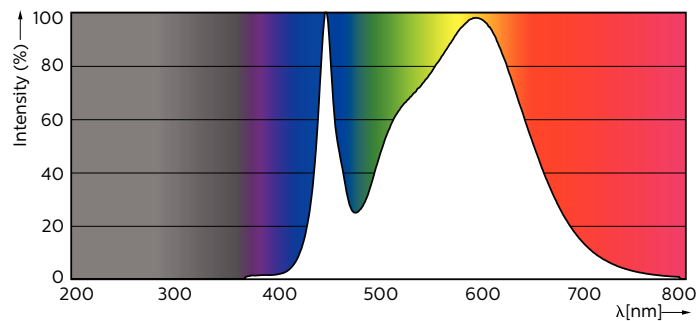


Spectral Power Distribution Colour - 8.5PL-C/T/COR/
26H-840/IF9/P/4P/DIM 10/1

General uniform lighting - 8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1


PL-C/T

Photometric data

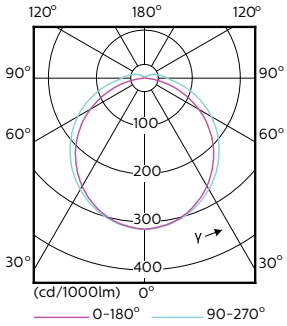


Light Distribution Diagram - 8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1


Lifetime

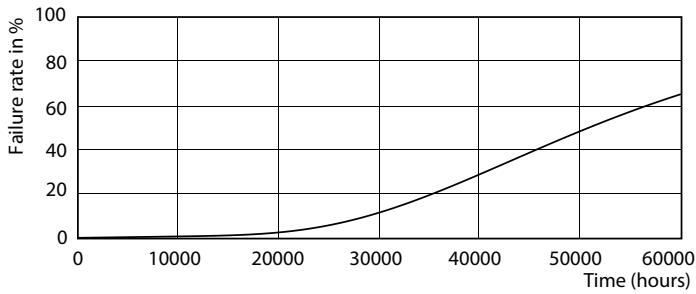


Life Expectancy Diagram - 8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1

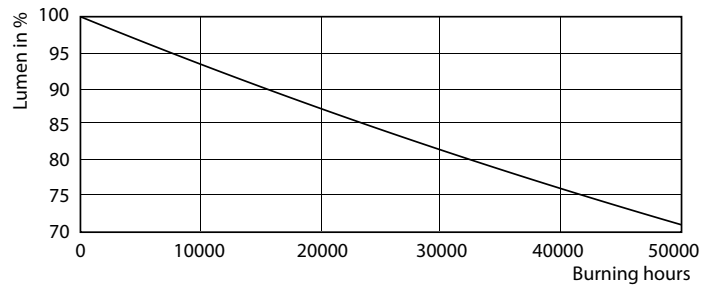

Lumen Maintenance Diagram - 8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1

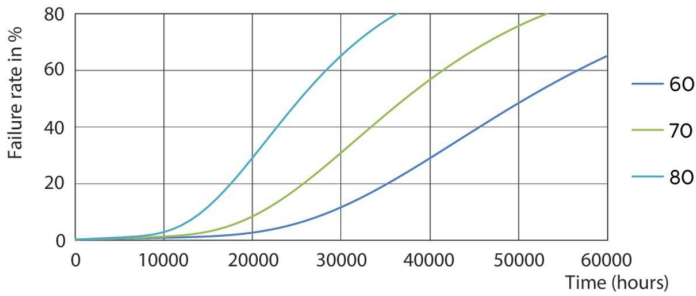


Life Expectancy Diagram - 8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1

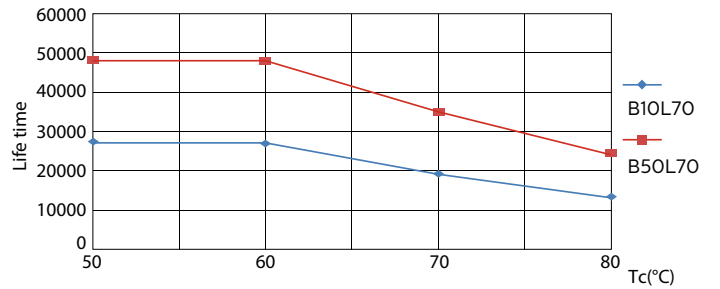

Life Expectancy Diagram - 8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM 10/1

PL-C/T

Lifetime

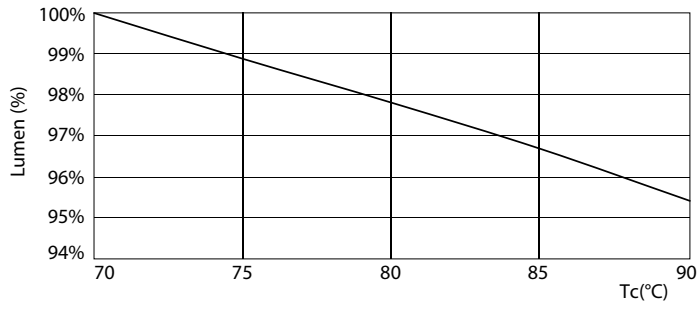

Lumen Maintenance Diagram - 8.5PL-C/T/COR/26H-840/IF9/P/4P/DIM
10/1

