



Energy Saver T2

EL/mdTQ 13W T2 4.1k

The Philips EnergySaver T2 provides energy efficient lighting in a smaller, sleeker, size that fits more fixtures. The energy saving T2 is a direct replacement for most incandescents, provides soft white light and lasts 11 years* reducing the hassle of frequent replacements.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	10,000 hour(s)
Switching Cycle	5,000
Rated Lifetime (Hours)	10,000 hour(s)
Lighting Technology	Compact Fluorescent Integrated
Light Technical	
Color Code	841 [CCT of 4100K]
Luminous Flux	900 lumen
Color Designation	Cool White (CW)
Chromaticity Coordinate X (Nom)	380
Chromaticity Coordinate Y (Nom)	380
Correlated Color Temperature (Nom)	4100 K
Luminous Efficacy (rated) (Nom)	67 lm/W
Color rendering index (CRI)	81
LLMF At End Of Nominal Lifetime (Nom)	50 %
Operating and Electrical	
Line Frequency	50 or 60 Hz
Input Frequency	50 or 60 Hz
Power Consumption	13.0 W
Lamp Current (Nom)	210 mA

Power Factor (Fraction)	0.55
Voltage (Nom)	110-127 V
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Shape	EL/mdTQS
Approval and Application	
Mercury (Hg) Content (Max)	2 mg
Energy Consumption kWh/1000 h	13 kWh
Product Data	
Order product name	EL/mdTQ 13W T2 4.1k
Order code	929689799501
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929689799501
Full product name	EL/mdTQ 13W T2 4.1k
EAN/UPC - Case	50046677414035
EAN/UPC - Product/Case	046677414030

Energy Saver T2

Dimensional drawing

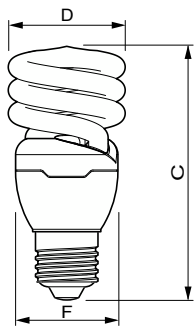

Product	D (max)	C (max)	F (max)
EL/mdTQ 13W T2 4.1k	51.5 mm	104.3 mm	42.5 mm

