



# InstantFit (UL Type-A) T5

## 24T5HO/46-835/IF33/P/DIM 10/1

The InstantFit TLED lamps provide hassle-free installation with simple lamp-for-lamp replacements. They deliver what we promise, with at least 40% energy savings, flicker-free performance, and the life you would expect. Other lamps claim compatibility but only InstantFit (UL Type-A) has been proven to work with over 200 ballasts and drivers, delivering even light output, with proven energy savings and a long average lifetime. End users will be delighted being under these comfortable and high quality InstantFit lamps with no visible flicker and optimized optics. Energy managers will enjoy the InstantFit lamps too as they can count the savings delivered by our lamps. To enjoy more energy savings, the InstantFit lamps can be paired with the Advance TLED drivers to create a Type C system.

### Product data


General Information		Color rendering index (CRI)	
Cap-Base	G5 [G5]		82
Nominal lifetime	50,000 hour(s)	LLMF At End Of Nominal Lifetime (Nom) 70 %	
Switching Cycle	50,000	Operating and Electrical	
Lighting Technology	LED	Line Frequency	40000-80000 Hz
EU RoHS compliant	Yes	Input Frequency	40000-80000 Hz
Light Technical		Power Consumption	24 W
Color Code	835 [CCT of 3500K]	Lamp Current (Max)	600 mA
Beam Angle (Nom)	140 degree(s)	Lamp Current (Min)	400 mA
Luminous Flux	3,300 lumen	Wattage Equivalent	54 W
Color Designation	White (WH)	Starting Time (Nom)	0.5 s
Correlated Color Temperature (Nom)	3500 K	Warm-up time to 60% light	0.5 s
Luminous Efficacy (rated) (Nom)	137.00 lm/W	Power Factor (Fraction)	0.9
Color Consistency	<5	Voltage (Nom)	39-64 V

# InstantFit (UL Type-A) T5

UL Type	UL Type A
<b>Temperature</b>	
Ambient temperature range	-20 °C to 45 °C
T-Case Maximum (Nom)	45 °C
<b>Controls and Dimming</b>	
Dimmable	Yes
<b>Mechanical and Housing</b>	
Bulb Finish	Frosted
Bulb Material	Plastic
Product Length	1,200 mm
Bulb Shape	T5
<b>Approval and Application</b>	
Energy Saving Product	Yes
Approval Marks	UL certificate RoHS compliance DLC compliance



Energy Consumption kWh/1000 h	- kWh
Energy Certifications	DLC Standard
<b>Application Conditions</b>	
can it be used in closed luminaires	Yes
<b>Product Data</b>	
Order product name	24T5HO/46-835/IF33/P/DIM 10/1
Order code	929001283804
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001283804
Full product name	24T5HO/46-835/IF33/P/DIM 10/1
EAN/UPC - Case	50046677467130
EAN/UPC - Product/Case	046677467135

## Dimensional drawing

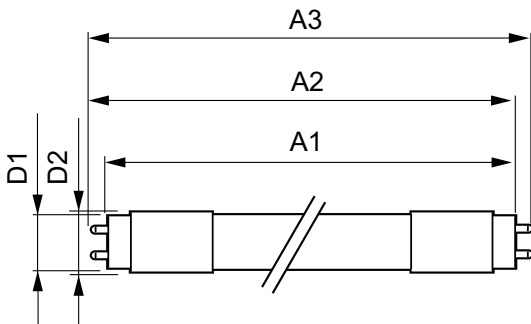

Product	D1	D2	A1	A2	A3
24T5HO/46-835/IF33/P/DIM 10/1	15.2 mm	17.8 mm	1,147.8 mm	1,154.9 mm	1,162 mm

## Photometric data

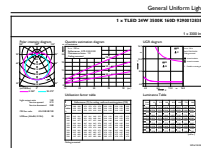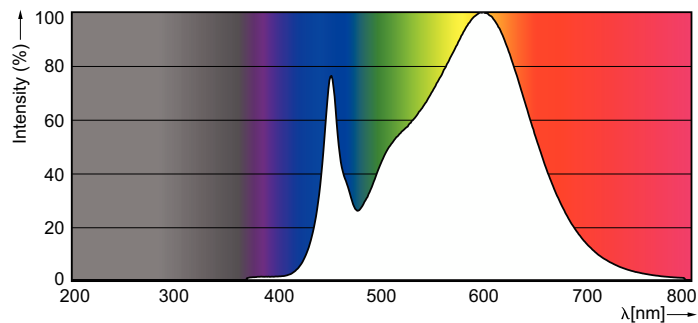


Spectral Power Distribution Colour - 24T5HO/46-835/IF33/P/DIM 10/1

General uniform lighting - 24T5HO/46-835/IF33/P/DIM 10/1

# InstantFit (UL Type-A) T5

## Photometric data

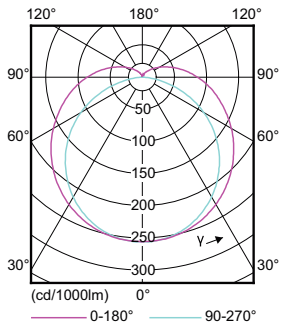

Light Distribution Diagram - 24T5HO/46-835/IF33/P/DIM 10/1

