



A-Shape LED

20A30/LED/865/FR/P/E26/ND 4/1FB

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.

Product data


General information	
Cap-Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	25000 h
Switching Cycle	50000
Light technical	
Color Code	865 [CCT of 6500K]
Beam Angle (Nom)	150 °
Luminous Flux (Nom)	2300 lm
Color Designation	Cool Daylight
Correlated Color Temperature (Nom)	6500 K
Luminous Efficacy (rated) (Nom)	115.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Nom)	20 W
Lamp Current (Nom)	175 mA
Wattage Equivalent	160 W
Starting Time (Nom)	1 s
Warm Up Time to 60% Light (Nom)	1 s

Power Factor (Nom)	0.9
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	85 °C
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A30 [A 30mm]
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Product data	
Order product name	20A30/LED/865/FR/P/E26/ND 4/1FB
EAN/UPC - Product	046677479282
Order code	929001854715
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001854715

A-Shape LED

Net Weight (Piece) 0.184 kg


Dimensional drawing

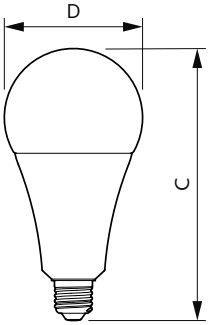


20A30/LED/865/FR/P/E26/ND 4/1FB

Product	D	C
20A30/LED/865/FR/P/E26/ND 4/1FB	95 mm	185 mm


Photometric data

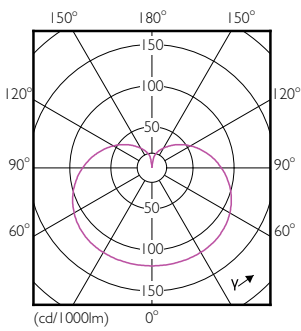

LEDbulb 20W A30 E26 865 15D ND

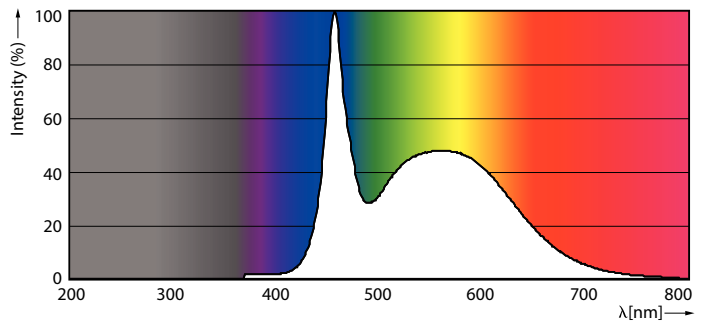



LEDbulb 20W A30 E26 865 15D ND

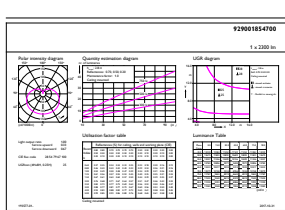

LEDbulb 20W A30 E26 865 15D ND

A-Shape LED

Lifetime

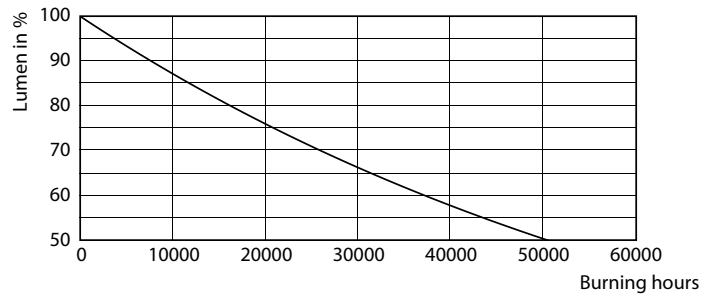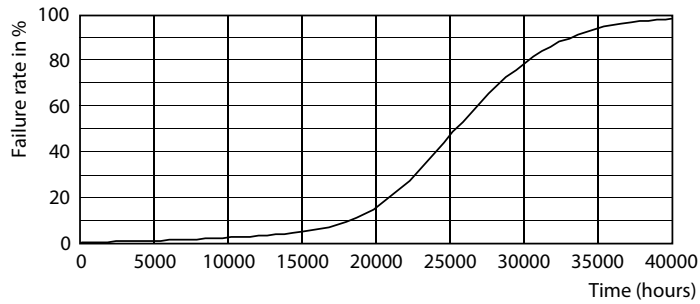

LEDbulb 20W A30 E26 865 15D ND

LEDbulb 20W A30 E26 865 15D ND

