



LED PAR38

13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	25,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
EU RoHS compliant	Yes
Light Technical	
Color Code	930 [CCT of 3000K]
Beam Angle (Nom)	40 degree(s)
Luminous Flux	1,200 lumen
Luminous Intensity (Nom)	2,500 cd
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	92.00 lm/W
Color Consistency	<4
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Line Frequency	50 to 60 Hz
Input Frequency	50 to 60 Hz
Power Consumption	13 W
Lamp Current (Nom)	120 mA


Wattage Equivalent	120 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.9
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	75 °C
Controls and Dimming	
Dimmable	Only with specific dimmers
Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	PAR38 [PAR 4.75 inch/121mm]
Approval and Application	
Suitable For Accent Lighting	Yes
Energy Certifications	Energy Star
Product Data	
Order product name	13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB

LED PAR38

Order code	929003030104
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929003030104
Full product name	13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB



EAN/UPC - Case	50046677567809
EAN/UPC - Product/Case	046677567804

Dimensional drawing

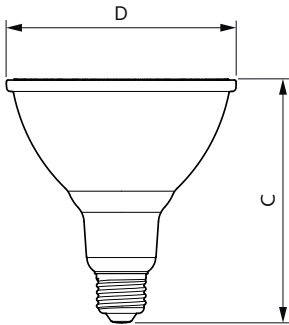


Product	D	C
13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB	122 mm	129 mm

Photometric data

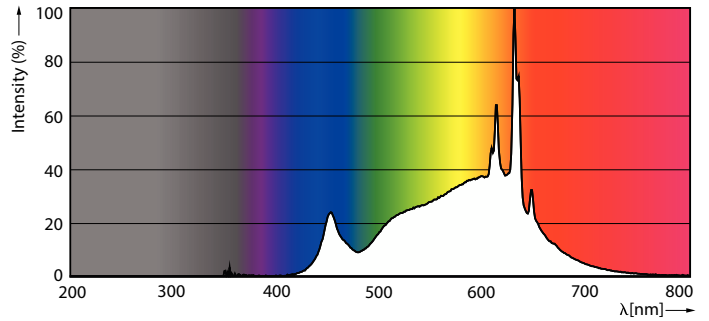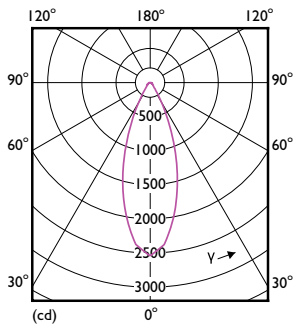

Light Distribution Diagram - 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB

Spectral Power Distribution Colour - 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB

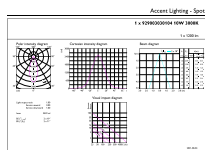

Accent Lighting Spots - 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB

LED PAR38

Lifetime



Life Expectancy Diagram - 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB

Lumen Maintenance Diagram - 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB

