



AimLite

W13GM LED Linkable Wraparound

DIMMABLE 3 CCT SELECTABLE



FEATURES

- Modern and sleek design with rounded edges for a more aesthetically pleasing result
- Narrower light opening to reduce glare and offer a more directional light output without leaking from the sides
- 4 000 K or 3 000/4 000/5 000 K selectable color temperature
- 0-10V dimming (dimming with row mounting only available when hardware using the end cap for conduit entry)
- Linkable with connectors (included in the box)
- Available in 2' and 4' lengths
- Perfect for surface and row-mounted installations
- This slim-profiled series is an ideal solution for commercial



AimLite

W13GM


T 514 227-1288

TF 1866 348-2374

aimlite.com

PART NO	DLC UNIQUE ID	WATTS [W]	VOLTS [V AC]	COLOR TEMP. [K]	LUMEN OUTPUT [LM]	EFFICIENCY [LM/W]	CRI	LIFE L70 [HRS]	TESTED HOURS LM-80 ³ [HRS]	DIMMING TYPE [YES/NO]	PF	THD [%]	CASE QTY [MASTER]
Dimmable													
2' SINGLE CCT													
W13GM-24-1-G2	PL2KEJQCDG06	23	120-277	4 000	2 695	115	84	54 000	9 000	YES	0.94	12	12
2' HIGH OUTPUT CCT SELECTABLE													
W13GM-24HO-3C-G2	S-EA4LTO	46	120-277	3 000/4 000/5 000	5 354	116	83	>72 000	12 000	YES	0.92	15	12
4' SINGLE CCT													
W13GM-48-1-G2	PL2MFXG4M4G3	47	120-277	4 000	5 420	116	84	54 000	9 000	YES	0.90	13	6
4' CCT SELECTABLE													
W13GM-48-3C-G2	S-LSWBN3	44	120-277	3 000/4 000/5 000	5 228/5 408/5 188	120	83	54 000	9 000	YES	0.90	20	6
Non Dimmable													
4' SINGLE CCT													
W13GM-48-1	-	47	120-277	4 000	5 043	106	84	54 000	9 000	NO	0.90	15	6

W13GM AT A GLANCE

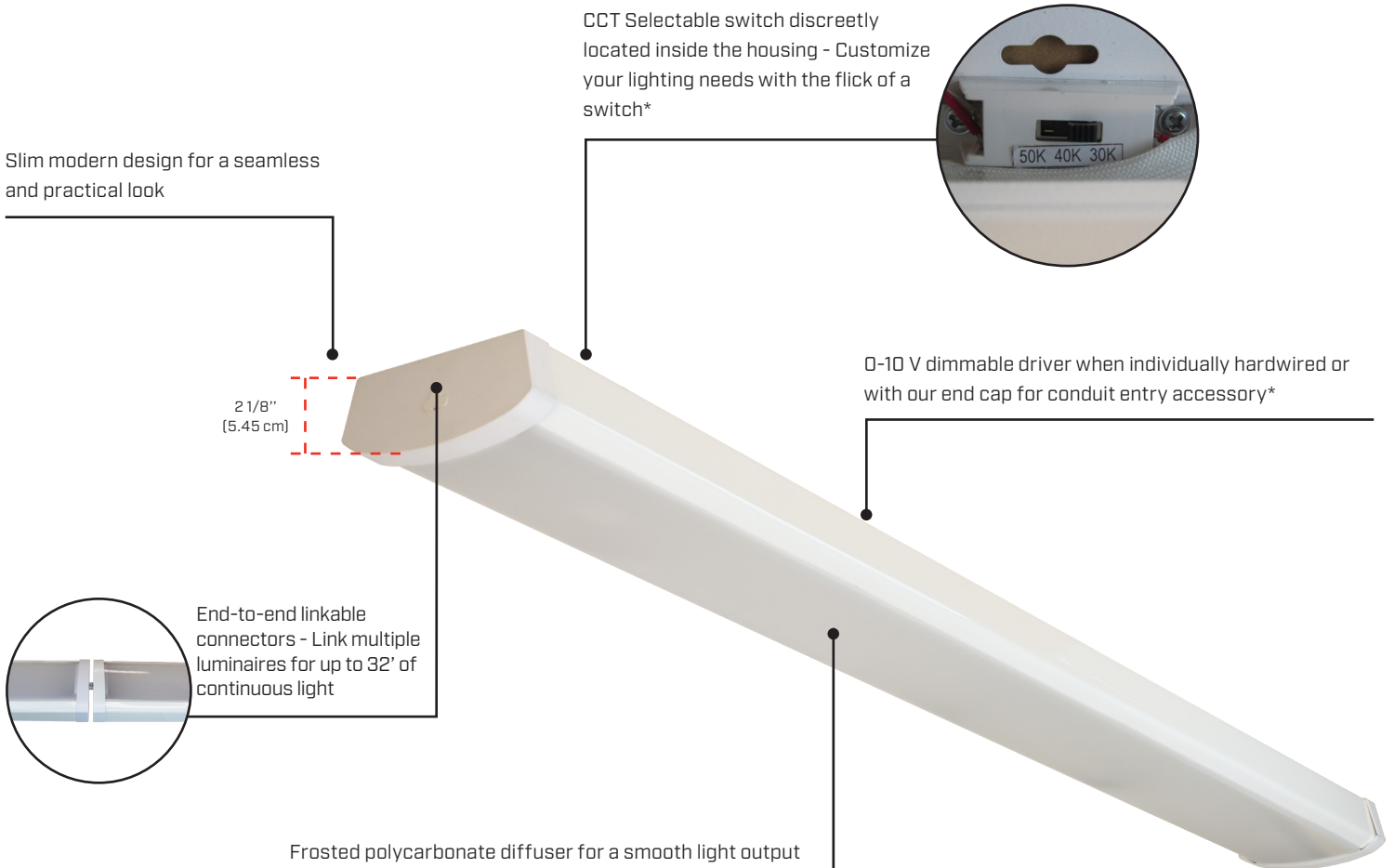

*If applicable