








Wire connector TA2.3 2 x 4 AWG...300 kcmil for 2 cables with control wire voltage tap-off 3 units accessories for: 3VA5 250

Model		
product brand name	SETRON	
product designation	accessories	
design of the product	circular conductor terminal	
accessories	Wire connector	
General technical data		
designation / of the terminal	TA2.3	
type of electrical connection / with control wire tap	Yes	
Connections according IEC		
connectable conductor cross-section		
<ul style="list-style-type: none"> <li>for copper cable / stranded / minimum</li> <li>for copper cable / stranded / maximum</li> <li>for aluminum cable / stranded / minimum</li> <li>for aluminum cable / stranded / maximum</li> </ul>	25 mm <sup>2</sup> 150 mm <sup>2</sup> 25 mm <sup>2</sup> 150 mm <sup>2</sup>	
stripped length	26 / 51 mm	
tightening torque / when using copper cables		
<ul style="list-style-type: none"> <li>stranded</li> <li>finely stranded</li> </ul>	25 - 150 mm <sup>2</sup> : 31.1 Nm 25 - 150 mm <sup>2</sup> : 31.1 Nm	
Connections according UL		
permissible temperature / of connectable conductor / according to UL 486A-486B	75 °C	
stripped length	1.0 / 2.0 in	
connectable conductor cross-section		
<ul style="list-style-type: none"> <li>for copper cable / stranded / minimum</li> <li>for copper cable / stranded / maximum</li> <li>for aluminum cable / stranded / minimum</li> <li>for aluminum cable / stranded / maximum</li> </ul>	4 AWG 300 kcmil 4 AWG 300 kcmil	
tightening torque / when using copper cables		
<ul style="list-style-type: none"> <li>stranded</li> </ul>	4 AWG - 300 kcmil: 275 lb-in	
Certificates		
General Product Approval	EMC	Declaration of Conformity
 UL	<a href="#">Miscellaneous</a>	
		
		
Marine / Shipping	other	Environment

Further information

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9233-0JC22>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9233-0JC22>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3VA9233-0JC22](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9233-0JC22)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

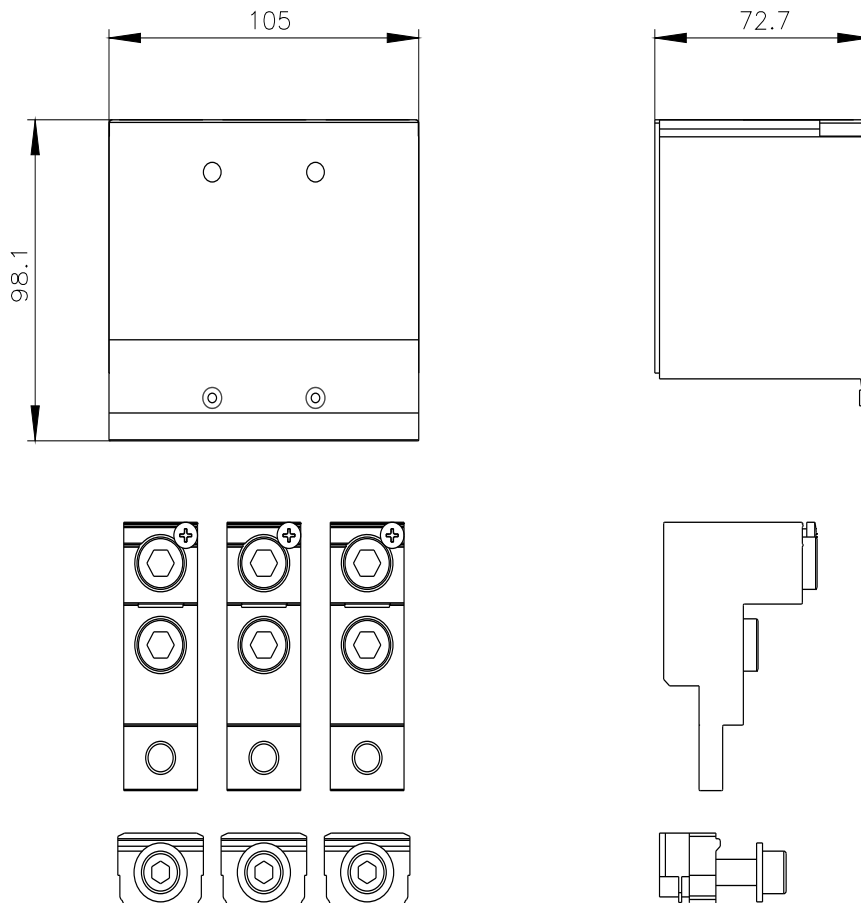

last modified:

10/25/2023

