



Trac-Master™ Designer Exclusives

A contemporary fixture collection for a range of applications

JUNO®



Designer Exclusives

Juno Designer Exclusives present a contemporary-yet-timeless appearance that is ideal for a broad range of commercial and residential applications, including task, accent and vertical surface lighting; as well as display,

exhibition and gallery lighting. This striking fixture collection provides effective, illumination and makes a bold statement no matter what the environment, no matter what the décor.

 


Trapezia™

Slender 9-inch or 16-inch long tubes conceal supply wires feeding into an elegantly sculpted die cast aluminum lamp housing. The light, airy appearance is great for display, exhibition and gallery lighting, and the downward reach can make pendant mounting of track unnecessary.

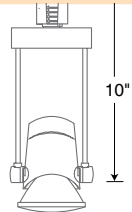
Finishes

White (WH)
 Black (BL)
 Silver (SL)

Series	Lamp	Dimensions
T630 9IN	12V, 20-50W MR16CG Cover Glass	

 
See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T635 9IN	35-75W PAR30	

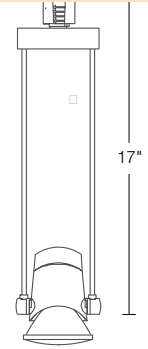
See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T630 16IN	12V, 20-50W MR16CG Cover Glass	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

 
 
Series	Lamp	Dimensions
T635 16IN	35-75W PAR30	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.

T537	
T538	

T640 with
T537 Transformer



 
T645

Gyrus™

A new spin on a traditional design, the Gyrus combines dramatic aerodynamic styling with the convenience of a front relamping gimbal ring. The MR16 has an integral accessory holder that accepts up to two standard 2" diameter lenses and louvers. An optional snap-in, dual accessory holder is available for the PAR30 that smartly integrates into the die cast aluminum fixture design.

Finishes

White (WH) Black (BL) Silver (SL)

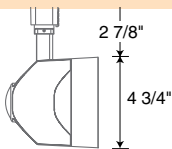
Series	Lamp	Dimensions
T640	12V, 20-50W MR16CG	

With integral Dual Accessory Holder

See specification sheet for optional accessories.

T537 and T538 Transformer required. Must be ordered separately.

Finishes: WH, BL, SL

 
 
Series	Lamp	Dimensions
T645	35-75W PAR30	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.

T537	
T538	

Aerodynamic Perfection

Reminiscent of precision aerodynamics, the Gyrus™ adds a touch of technical elegance to your environment. With the convenience of front relamping and the versatility of dual-accessory capability, Gyrus represents the perfect marriage of functionality and style.



Wireforms®

Timeless, patented Wireform design encircles line and low voltage halogen lamps in a light, technically appealing frame.

Finishes

White (WH) Black (BL)** Silver (SL) Satin Chrome (SC) Red (RD)

** Black finish lampholders are supplied with both black and red adjusting buttons.

Series	Lamp	Dimensions
T430	12V, 20-75W MR16	

See specification sheet for optional accessories.

T537 and T538 Transformer required. Must be ordered separately.

Finishes: WH, BL

Series	Lamp	Dimensions
T433	35-50W PAR20	

See specification sheet for optional accessories.

Finishes: WH, BL, SL, SC

Series	Lamp	Dimensions
T431	45-60W PAR16	

Accessory for T431: Black Barn Doors T74BL 175

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T435	35-75W PAR30	

See specification sheet for optional accessories.

Finishes: WH, BL, SL, SC

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.

T537	
T538	

Series	Lamp	Dimensions
T437	45-250W PAR38	

See specification sheet for optional accessories.

Finishes: WH, BL, SL, RD



Wishbones

An elegant twist on the popular gimbal ring fixture, the sculpted "wishbone" yoke and contoured socket cup produce a most pleasing combination of form and proportion. A special 360 degree plus rotation feature on this series eliminates aiming dead zones. Aiming and rotation can be locked with a Phillips screwdriver.



Finishes
 White (WH) Black (BL) Silver (SL) Satin Chrome (SC) (With Black Yoke)

Series	Lamp	Dimensions
T480	12V, 20-50W MR16	

See specification sheet for optional accessories.

T537 and T538 Transformer required. Must be ordered separately.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T483	35-75W PAR30	

See specification sheet for optional accessories.

Finishes: WH, BL, SL, SC

Series	Lamp	Dimensions
T485	12V, 35-75W AR111	

See specification sheet for optional accessories.

Finishes: WH, BL

Series	Lamp	Dimensions
T487	45-150W PAR38	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T482	35-50W PAR20	

See specification sheet for optional accessories.

Finishes: WH, BL, SL, SC

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.

T537	
T538	

T216
with T537
Transformer

TP216
with T537
Transformer

T218

T219

Delta 200 Series®

An angular, die-cast aluminum fixture body and rod-supported lamp bezel, create a semi-exposed, technical appearance. The front bezel supports accessory lenses and louvers for custom-tailored lighting effects.

Finishes

White (WH) Black (BL) Silver (SL)



Series	Lamp	Dimensions
T216	12V, 20-50W MR16	

See specification sheet for optional accessories.

T537 and T538 Transformer required. Must be ordered separately.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T218	35-75W PAR30	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
TP216	12V, 20-50W MR16	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

 
 
Series	Lamp	Dimensions
T219	45-150W PAR38	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.





Flybacks

Uniquely angled back from the track at 45 degrees, Flybacks add visual energy into a space.

Finishes

White (WH)
 Black (BL)
 Satin Chrome (SC)

Series	Lamp	Dimensions
T227	12V, 20-50W MR16CG Cover Glass	

See specification sheet for optional accessories.

T537 and T538 Transformer required. Must be ordered separately.

Finishes: WH, BL

Series	Lamp	Dimensions
T228	35-75W PAR30	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T229	45-150W PAR38	

See specification sheet for optional accessories.

Finishes: WH, BL

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.

T537	
-------------	--

T538	
-------------	--



Close-Ups

As the name implies, this compact, stylish lampholder hugs close to the trac for minimum intrusion into a space. The softly sculpted back detail and metal shades are welcome design refinements for many interiors.

Finishes

White (WH)
 Black (BL)
 Satin Chrome (SC) (With Black Socket Housing)



Series	Lamp	Dimensions
T220	35-50W PAR20 Enclosed Shade	

Finishes: WH, BL, SC

Series	Lamp	Dimensions
T238	45-150W PAR38 Open Fixture	

Finishes: WH, BL

Series	Lamp	Dimensions
T230	35-75W PAR30 Open Fixture	

Finishes: WH, BL

Series	Lamp	Dimensions
T239	45-150W PAR38 Enclosed Shade	

Finishes: WH, BL

Series	Lamp	Dimensions
T231	35-75W PAR30 Enclosed Shade	

Finishes: WH, BL, SC



Theatrical Lights

The classic stage and studio design and integral barn doors evoke the feeling of theatrical lighting.

Finishes

Black (BL)

Series	Lamp	Dimensions
T290	12V, 20-75W MR16	

 
 
See specification sheet for optional accessories.

T537 and T538 Transformer required. Must be ordered separately.

Finishes: BL

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.



Series	Lamp	Dimensions
T295	30-50W R20 or 35-50W PAR20	

See specification sheet for optional accessories.

Finishes: BL

Studio I

This classic nautical look is especially popular in traditional design settings.

Finishes

White (WH)

Series	Lamp	Dimensions
T393	30-50W R20	

See specification sheet for optional accessories.

T537 and T538 Transformer required. Must be ordered separately.

Finishes: WH

Series	Lamp	Dimensions
T395	60-75W BR30 or 35-75W PAR30L	

See specification sheet for optional accessories.

Finishes: WH

Series	Lamp	Dimensions
T397	45-150W PAR38 or 65-120W BR40	

See specification sheet for optional accessories.

Finishes: WH



T291
with T537
Transformer

T293

T294

T292

T296

Studio II

Add theatrical styling to lighting applications. Striking finishes to innovative product details make the Studio II an important design element and an effective lighting product. Available with or without integral barn doors, Studio II adds a contemporary stage and studio flavor into an environment. Supplied with integral accessory holder.

Finishes

White (WH) Black (BL) Silver (SL)

Series	Lamp	Dimensions
T291	12V, 20-50W MR16 with Black Integral Accessory Ring	


See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T293	35-75W PAR30 with Black Integral Accessory Ring	

See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T294	45-150W PAR38 with Black Integral Accessory Ring	

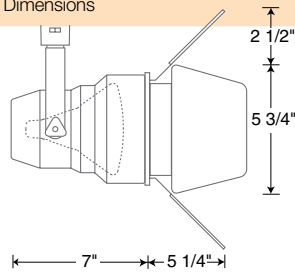
See specification sheet for optional accessories.

Finishes: WH, BL, SL

Series	Lamp	Dimensions
T292	35-75W PAR30 with Barn Doors	

See specification sheet for optional accessories.

Finishes: BL, SL

 
Series	Lamp	Dimensions
T296	45-150W PAR38 with Barn Doors	

 
See specification sheet for optional accessories.

Finishes: BL, SL

20-75VA 12V Transformers

Both T537 and T538 are available in white, black or silver finishes.

T537	
-------------	---

T538	
-------------	---



Juno[®]

©2017 Acuity Brands Lighting, Inc. The marks appearing in this catalog are trademarks of Acuity Brands Lighting, Inc. Products shown in this brochure may be covered by U.S. and international patents and patents pending. Specifications subject to change without notice. Printed in the U.S.A.