

# SPEXS-2L/SPEXS12-2L

## “EASY OUT” EXIT STEEL COMBO

### SPEXS-2L

6VDC 36W Battery Capacity (Over 4 hours Duration Standalone Unit)  
2 x 2W Crisp White LED Heads

### SPEXS12-2L

12VDC 72W Battery Capacity (Over 8 hours Duration Standalone Unit)  
2 x 2.5W Crisp White LED Heads



**Approvals:**

CSA Certified to C22.2 #141.15

Energy Verified  
Energie Vérifiée

### DESCRIPTION

The commercial SPEXS-2L/SPEXS12-2L features a slim profile that prevents light leaks. Easy to install design, available in 6VDC 36W with over 4 hours duration and 12VDC 72W with over 8 hours duration.



### CIRCUITRY

- 120/347V AC 60Hz input, field selectable
- 1.9W power consumption on AC input for LED exit portion of combination sign
- LED Emergency DC wattages as follows: 6VDC = 0.9W; 12VDC = 1.8W
- 6VDC 36W or 12VDC 72W emergency power output versions (as specified)
- Momentary push button test switch
- Pilot LED for AC ON and CHARGE
- Fully automatic, current limited charger
- Solid state design and construction
- Brownout and short circuit protection
- Temperature compensated
- Maintenance free, sealed lead acid battery

### MECHANICAL

- 20 Gauge steel construction
- Slide out faceplates and backplates for rapid and simple installation
- Universal spider knockout pattern stamped into backplate for junction box mounting
- Universal models include ceiling or end mount, field installable canopy kit c/w spider plate
- Front head mounting is standard
- Multiple conduit entry knockouts
- White powder coat finish standard
- PAR18 small style, high impact thermoplastic heads
- LED heads with limited lifetime warranty\*

### DIMENSIONS

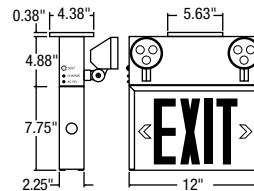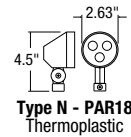

### ORDERING GUIDE

Series
<b>SPEXS-2L</b>
<b>SPEXS12-2L</b>

### MODEL RATING

Model	Voltage	Wattage capacities			
		30 min.	60 min.	90 min.	120 min.
<b>SPEXS-2L</b>	6V	36	18	12	9
<b>SPEXS12-2L</b>	12V	72	36	24	18

**QUICK SHIP:** Not all products are Quick Ship. To view our Quick Ship qualified products, please consult our Quick Ship Product Guide at [stanprols.com/quick-ship-product-guide](http://stanprols.com/quick-ship-product-guide). Product availability is subject to change without notice. Please contact your Stanpro customer service representative to confirm inventory levels at time of order.

\* For complete warranty details, please see our terms and conditions in our website.