


ACCESSORIES - PLATES & COATINGS

Ground Bars

CAT No:	Size	Description
BB-GRND-C-12	12 in 1/4 x 2	Bare Copper Ground Bar- c/w Insulators
BB-GRND-C-19	19 in 1/4 x 1	Bare Copper- Rack Mount Ground Bar

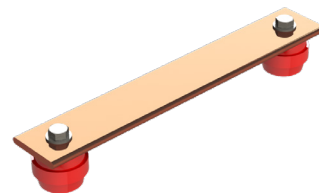

Neoprene Oil Resistant Self adhering

CAT No:	Size	Feet Per Roll
GASKET-BLACK-0025x0100	1/4x1	
GASKET-BLACK-0025x0075	1/4x3/4	
GASKET-BLACK-0012x0075	1/8x3/4	
GASKET-BLACK-0012x0100	1/8x1	


Cork gasket available upon request.

ACCESSORIES



Red Standoff Insulators:

CAT No: INS-RED
1 3/8 High; 1 3/4 Wide
3/8 Thread size
Other sizes available upon request.

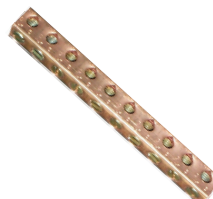

Copper Neutral Bar:

CAT No: N-174
Accepts 14 - 6 wire size.
Sold per inch. 69" max




Touch Up Spray Paint:

CAT No: 880-PG
ASA-61 Grey



ENCLOSURE QUICK ORDER FORM

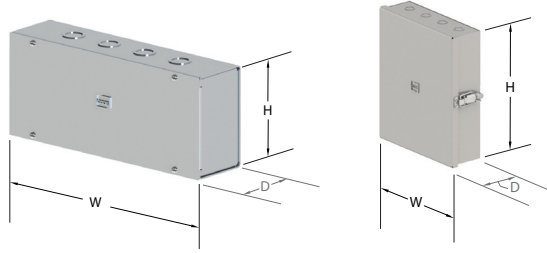

MATERIAL: ALUMINUM GALVANIZED POWDER COATED STEEL STAINLESS

CLASSIFICATION: CSA 1 CSA 3 or 3R CSA 4 CSA 4X

DIMENSIONS: (H) HEIGHT _____ (W) WIDTH _____ (D) DEPTH _____

STYLE: HINGED or SCREW COVER FREE STANDING or WALL MOUNTABLE

FINISH: RAW METAL POWDER COATED


POWDER COAT COLOUR: ASA61 Grey COLOUR RAL# _____

CUT OUTS: NO YES - ADD TO DRAWING ABOVE

ACCESSORIES: BACK PAN KEY LOCK TAMPER PROOF SCREWS

QUANTITY: _____ **REQUESTED BY DATE:** _____ **DRAWING ATTACHED:** ATTACHED

NOTES:

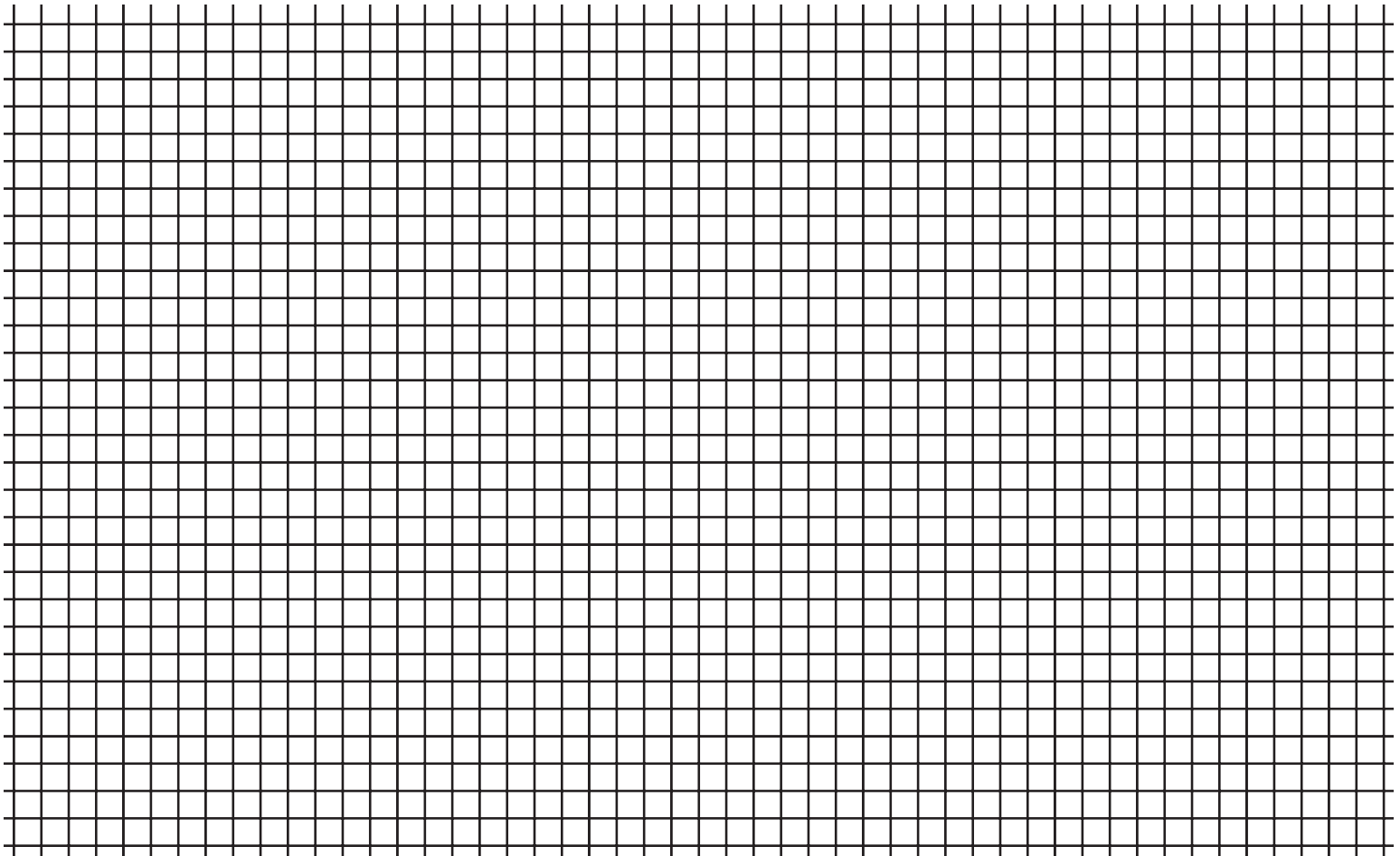

10 THE TOP REASONS WHY CUSTOMERS CHOOSE

CODE

01



Made in Canada

02



Quick Delivery
Direct to site & feed job

03




C.S.A. Approved

04



Stocked Locally, Onsite

05

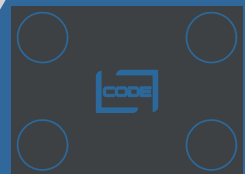

Connector Plates - SPYDERLOK
Quick & easy to install

06



Materials
Aluminum, Pre-Galv, Stainless, Paint Ready

07




Smooth Edges
Free from burrs

08



Back Welding for Strength

09

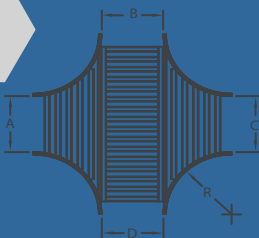

Custom Fabrication
To meet all unique onsite applications

10



Technical Support

