


 








Model		Finish	Specification
REC-EXT108 		White	108" extension cord for recessed lights One end with male connector and one end with female connector Quick-connect installation Can be connected together up to 40 feet (4 extension cords)
REC-EXT230 		White	230" extension cord for recessed lights One end with male connector and one end with female connector Quick-connect installation Can be connected together up to 40 feet (2 extension cords)
REC-PT4-BB REC-PT4-BK REC-PT4-SN 		Brushed Brass Black Satin Nickel	4" recessed panel trim Compatible products: SPN4, 2004, 5004, SM-PNL4
RTF4-TRIM-BK RTF4-TRIM-SN 		Black Satin Nickel	4" recessed panel trim Compatible products: RTF4-3K, RTF4-CC
DDP4-TRIM-BK DDP6-TRIM-BK 		Black	4" and 6" recessed panel trims Compatible products: DDP4-CC, DCP-DDP4, DDP6-CC, DCP-DDP6

Model	Size	Watts	Delivered lumens	CRI	Color °T	Voltage
COBTP1M	39"	12 W	550 lm	90	3000 K	12 V
COBTP3M	118"	24 W	1500 lm	90	3000 K	12 V
COBTP5M	196"	48 W	2250 lm	90	3000 K	12 V
COBTP-REEL*	20m (65')	8 W /meter	500 lm /meter	90	3000 K	12 V

*20m COB reel does not include a 12V driver. Plug-in or hard-wired power supply required for installation. Sold separately.

Specifications

12V DC LED plug-in driver included
(1m=12w / 3m=24w / 5m=48w)
Excellent color rendering
Seamless light emission (360 LEDs/meter)
Warm white light output
Superior LED performance and lifespan
Over 50,000 hours of service life
Can be cut at every cut mark (every 2 cm)
Maximum run length of 5m (196") in a series
Dimmable with DALI dimming power supply and most low-voltage electronic dimmers
Refer to website for dimmer compatibility
3-year warranty

Power supplies: plug-in

ETR-LED10WPI
12VDC/10W class 2 LED driver

ETR-LED24WPI
12VDC/24W class 2 LED driver

Power supplies: hard-wired

BT06DIM-IC
6W dimmable LED hardwire driver

BT12DIM-IC
12W dimmable LED hardwire driver

BT24DIM-IC
24W dimmable LED hardwire driver

BT36DIM
36W dimmable LED hardwire driver

BT48DIM
48W dimmable LED hardwire driver

Accessories

COBTP-ALXT-BK
1 meter black aluminum extrusion with black lens

COBTP-ALXT-WH
1 meter white aluminum extrusion with white lens

COBTP-ALXT-L5M
5 meter white lens for extrusions

COBTP-EXT02
2" extension with reconnect connectors

COBTP-EXT24
24" extension with reconnect connectors


COBTP-EXT60
60" extension with reconnect connectors

COBTP-CC06
Connection cord for hard-wired driver installation



COBTP1M	1 x 39"
COBTP3M	1 x 118"
COBTP5M	1 x 196"
COBTP-REEL*	1 x 20m (65')

* Driver not included

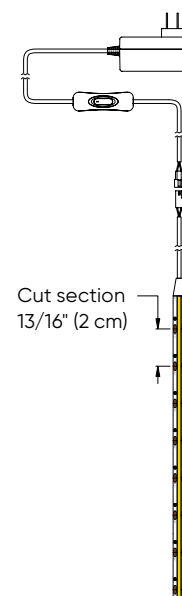

Model	Size	Watts	Delivered lumens	CRI	Color °T	Voltage
DCP-PNL4WH	4"	14 W	750 lm	90	RGB + 2700 K - 6500 K	120 V
DCP-PNL6WH	6"	20 W	1200 lm	90	RGB + 2700 K - 6500 K	120 V

Specifications

Includes a junction box with integrated driver
 Over 50,000 hours of service life
 Full color spectrum
 2700K - 6500K in pure whites
 Dimmable through the Dals Connect app only
 Bluetooth mesh technology
 Minimal heat emission
 Aluminum construction
 Suitable for wet locations
 3-year warranty

Finish

WH White

Order example

DCP-PNL4WH
 4" RGB+CCT smart Bluetooth fixture with embedded smart module which you can control with your smartphone

Note

Add the DALS Connect Pro Hub for even greater flexibility: voice control, remote access, expanded mesh network, ability to connect 128 devices per Hub.

Download the Dals Connect app

Create groups
 Set schedules
 Remote access*
 Compatible with Google Assistant and Amazon Alexa*



*Hub needed

