


COLUMN

20" / 30" LANDSCAPE BOLLARDS

The Column series, a robust rectangular bollard that features a minimalist design for the ultimate in urban sophistication.

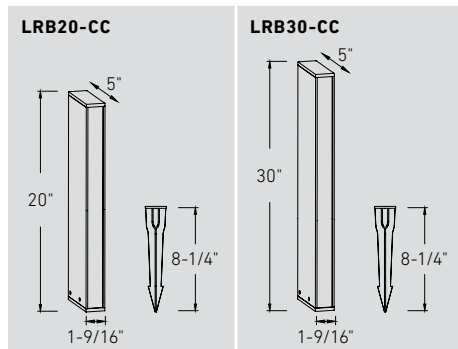

Model	Size	Watts	Lumens	CRI	Color °T	Voltage
LRB20-CC	20"	12 W	600 lm	80	2200, 2700, 3000, 3500, 4000 K	12 VAC
LRB30-CC	30"	13 W	700 lm			

 
Specifications

Excellent color rendering
 Switch-selectable CCT: 2200K/ 2700K/ 3000K/ 3500K/ 4000K
 Superior LED performance and lifespan
 109° beam angle
 Can be mounted to wood or concrete
 Over 50,000 hours of service life
 Cast aluminum construction
 Suitable for wet locations
 5-year warranty

Finish

● **BK** Black

Beam angle



What's included

Light fixture with CCT switch
 Plastic ground stake
 Mounting bracket
 Waterproof wire nuts


Accessories

LAN-ACC-PS
 8-1/4-inch plastic ground stake
LCBL-50-16
 50 feet, 16 gauge low-voltage wiring
LCBL-100-16
 100 feet, 16 gauge low-voltage wiring
LCBL-50-14
 50 feet, 14 gauge low-voltage wiring
LCBL-100-14
 100 feet, 14 gauge low-voltage wiring
LCBL-100-12
 100 feet, 12 gauge low-voltage wiring
LCBL-200-12
 200 feet, 12 gauge low-voltage wiring

TRANSFORMERS

60W / 300W TRANSFORMERS

Outdoor low-voltage transformers with timer and photocell sensor, 120 VAC to 12V / 13V / 14V / 15V AC, weatherproof.

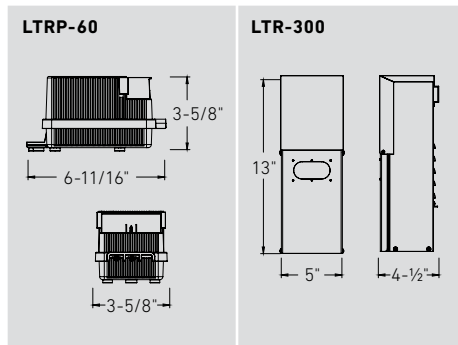

Model	Input	Output	Output power
LTRP-60	120 VAC / 60Hz	12 VAC	60 W
LTR-300	120 VAC / 60Hz	12 / 13 / 14 / 15 VAC	300 W

Specifications

Constant voltage mode power supply
 Protection: short circuit / over voltage
 Maximum load: 80%
 Operating temperature: -30°C to 45°C
 Photosensor with programmable ON-time (60W: 2-8 hrs, 300W: 1-9 hrs)
 Suitable for wet locations
 5-year warranty

Finish

● **BK** Black

What's included

Low-voltage transformer

Note

For more on wiring lengths, see Voltage Drop charts, beginning on page 12.














LANDSCAPE ACCESSORIES

Model		Compatibility	Finish	Description
LAN-ACC-MS		LSP3-CCL-BK, LSP4-CCL-BK	Black	Metal ground stake
LAN-ACC-PS		LPL26-CC-BK, LPP20-CC-BK, LRB20-CC-BK, LRB30-CC-BK	Black	Plastic ground stake
LCBL-50-16 LCBL-100-16 LCBL-50-14 LCBL-100-14 LCBL-100-12 LCBL-200-12		LSP3-CCL-BK, LSP4-CCL-BK, LPL26-CC-BK, LPP20-CC-BK, LRB20-CC-BK, LRB30-CC-BK	Black	16, 14, and 12 gauge low-voltage wire in 50, 100, and 200 ft. lengths.
LSP-EXT04		LSP3-CCL-BK, LSP4-CCL-BK	Black	4 in. extension arm
LSP-WM		LSP3-CCL-BK, LSP4-CCL-BK	Black	Spotlight wall/surface mount adapter



SMART LANDSCAPE ACCESSORIES

Model		Compatibility	Finish	Description
DCP-PTR36		DCP-SPT6, DCP-GRD4, DCP-FLD30, DCP-BRK12, DCP-RK10, DCP-RK18, DCP-CPL24, DCP-STK20, DCP-STK50	Black	36W plug-in driver
DCP-ACC-MS06		DCP-SPT6, DCP-GRD4, DCP-FLD30, DCP-RK10, DCP-RK18, DCP-CPL24, DCP-STK20, DCP-STK50	Black	6-inch metal ground stake
DCP-ACC-MS12		DCP-SPT6, DCP-GRD4, DCP-FLD30, DCP-RK10, DCP-RK18, DCP-CPL24, DCP-STK20, DCP-STK50	Black	12-inch metal ground stake
DCP-ACC-MB		DCP-SPT6, DCP-GRD4, DCP-RK10, DCP-RK18, DCP-CPL24, DCP-STK20, DCP-STK50	Black	Surface mounting bracket
DCP-EXT6FT		DCP-SPT6, DCP-GRD4, DCP-FLD30, DCP-BRK12, DCP-RK10, DCP-RK18, DCP-CPL24, DCP-STK20, DCP-STK50	Black	6-foot extension cable
DCP-EXT20FT		DCP-SPT6, DCP-GRD4, DCP-FLD30, DCP-BRK12, DCP-RK10, DCP-RK18, DCP-CPL24, DCP-STK20, DCP-STK50	Black	12-foot extension cable
DCP-EXT-T		DCP-SPT6, DCP-GRD4, DCP-FLD30, DCP-BRK12, DCP-RK10, DCP-RK18, DCP-CPL24, DCP-STK20, DCP-STK50	Black	6-inch T-connector
DCP-SPTTEXT14		DCP-SPT6	Black	14-inch extension tube for Orbit spot light
DCP-SPTACCLENS		DCP-SPT6	-	120° frosted lens for Orbit spot light
DCP-STGACCBULB		DCP-STG48	-	Replacement bulb for Orion string light
DCP-STGACCPCB		DCP-STG48	-	Replacement PCB for Orion string light