



A-Shape LED

16A21/PER/827-22/P/E26/WG 6/1FB

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.


Product data

General information	
Cap-Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Light technical	
Color Code	822-827 [tunable warm white]
Beam Angle (Nom)	250 °
Luminous Flux (Nom)	1600 lm
Color Designation	Warm White (WW)
Luminous Efficacy (rated) (Nom)	100.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	60 Hz
Power (Nom)	16 W
Lamp Current (Nom)	180 mA
Wattage Equivalent	100 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.8

Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	90 °C
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Bulb Finish	Frosted
Bulb Shape	A21 [A 21mm]
Approval and application	
Energy Consumption kWh/1000 h	- kWh
Product data	
Order product name	16A21/PER/827-22/P/E26/WG 6/1FB
EAN/UPC - Product	046677479480
Order code	929001837704
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001837704
Net Weight (Piece)	0.058 kg

A-Shape LED



Dimensional drawing

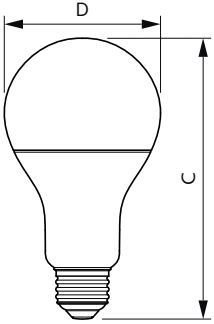

16A21/PER/827-22/P/E26/WG 6/1FB


Product	D	C
16A21/PER/827-22/P/E26/WG 6/1FB	78 mm	140 mm

Photometric data

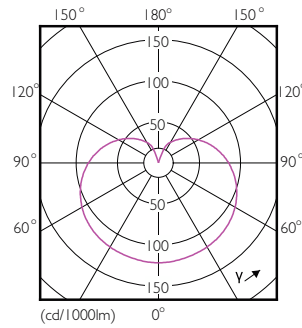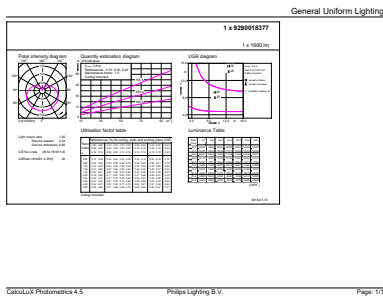

100W E26 A21 FR 250D 822-827 2200-2700K



75W E26 A21 FR 250D 822-827 2200-2700K

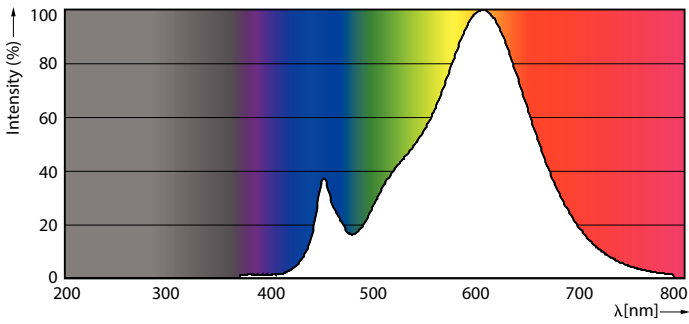

40W E26 A19 FR

A-Shape LED

Lifetime

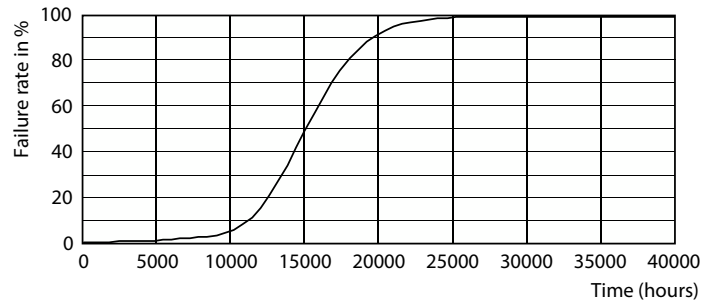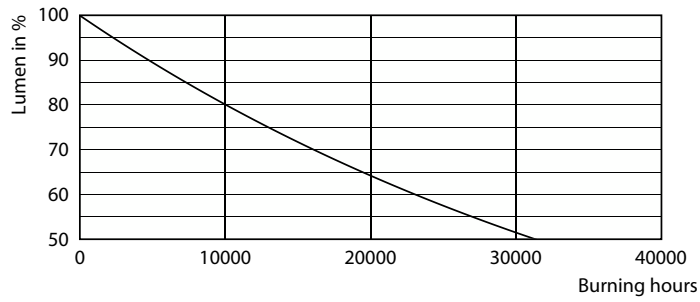

40W E26 A19 FR

40W E26 A19 FR

