
 


# Compact Splicing Connectors, 222 Series LEVER-NUTS®

<b>Cross section:</b>	<b>28 – 12 AWG</b> (solid, stranded and flexible)	
<b>Electrical specs:</b>	<b>600 V (1000 V signs and fixtures)</b> 20 A maximum * Based on 2008 NEC current rating of max conductor size	
<b>Strip length:</b> 	<b>9 - 10 mm / 0.37 in</b>	
<b>Maximum operating temperature: 105° C</b>		<b>Approvals: UL, ENEC, PSE, ABS</b>  <b>Also approved for grounding and bonding</b>

For all connections requiring...

- Stranded / solid wires
- Wide range of wire sizes
- Combination of different wire sizes and types in one connector
- Small space consumption
- Built-in test point
- Protection against electrical shock, touch safe
- Low installed cost and safe operation
- Maintenance-free connection
- A reusable connector

2-conductor connector






3-conductor connector



5-conductor connector



Item No.	Pack.-unit pcs	Item No.	Pack.-unit pcs	Item No.	Pack.-unit pcs
222-412		222-413		222-415	
222-412/K194-4045	50 pc box (1=50)	222-413/K194-4045	50 pc box (1=50)	222-415/K194-4045	40 pc box (1=40)
222-412/PW05-0005	5 pc blister pack	222-413/PW05-0005	5 pc blister pack	222-415/PW05-0005	5 pc blister pack
222-412/PW05-350	350 pc jar	222-413/PW05-250	250 pc jar	222-415/PW05-150	150 pc jar
222-412/VE00-2500	2,500 pc bulk bag	222-413/VE00-2500	2,500 pc bulk bag	222-415/VE00-1000	1,000 pc bulk bag

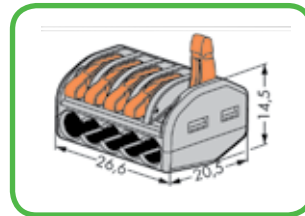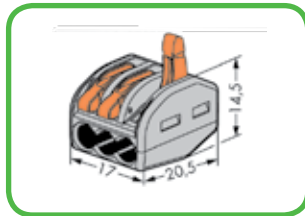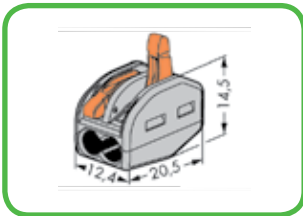

Accessories	Item No.	Pack.-unit pcs
Wire cutting and stripping tool (34-8 AWG)	206-124	1
Operating tool for Series 222	210-101	1



Operating tool



Wire cutting and stripping tool

## Packaging Options



Box



Blister Pack



Jar