

# SLIMLED ORIGINAL

4", 680-940 Lumens, 9-12W, Color Selectable  
Recessed Downlighting

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

## Features

### Body

Durable airtight aluminum body with UV stable paint and white PMMA diffuser lens for low glare. Includes silicone gasket for wet location applications.

### LED Characteristics

This general application light fixture features a 9 watt (for standard output) or 12 watt (for high output) LED module that maintains uniform intensity producing up to 940 lumens; with a typical CRI of 90. Available with 5 step CCT switch on the driver (2700 K, 3000 K, 3500 K, 4000 K and 5000 K).

### Dimming

100%-10% dimming capability. This fixture is compatible with industry standard forward/reverse phase or TRIAC/ELV dimmers. For compatible dimmers, visit [www.liteline.com/SlimLEDOOriginal](http://www.liteline.com/SlimLEDOOriginal).

### Beam Spread

The fixture lens provides 110° beam spread.

### Mounting

Includes two spring loaded clips to attached to any ceiling material.

### LED Driver

Steel hardwire box with 200mA (for standard output) or 280mA (for high output) dimmable class II electronic LED driver with 100-135V AC input. Includes an 18" plenum rated FT4 wire with DC 2.1 connector from driver to fixture.

### Quick Connect push-in terminals

"Quick connect" push-in terminals for fast and easy wiring.


### Operating Temperature

-30°C~35°C (-22°F~95°F)

### Environment


- Suitable for wet locations.
- Suitable for insulated ceiling applications.
- Indoor/outdoor

SPECIFICATION	
TM-30 Annex E	P2 / V- / F3
Application	Ceiling Recessed Mount
Approved Location	Wet / Insulated Ceilings
Beam Angle	110°
CCT	2700 K / 3000 K / 3500 K / 4000 K / 5000 K
Certification	cETLus
Color	BK / WH
CRI	90
Dimming	Yes
Dimming Tech	Forward/Reverse phase / TRIAC/ELV
Energy Star	Yes
Hole Cut	Ø 4¼" (108mm)
Input	100-135V AC, 60Hz
LM79	Yes
LM80	Yes
Lumens	Up to 940
Lumens per Watt	Up to 85
Power Factor	>0.9
Projected Life	70% @ 50,000 hrs
Title 24	JA8
Warranty	3-Years
Wattage	9W / 12W

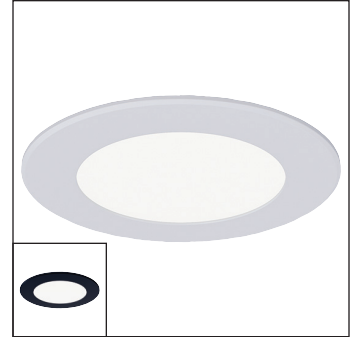

## Description

A slender, low-profile downlight that not only excels in performance but also makes residential installation a breeze. This downlight solution offers impressive light output, energy efficiency and a modern, streamlined design. Made to excel even in wet environments.

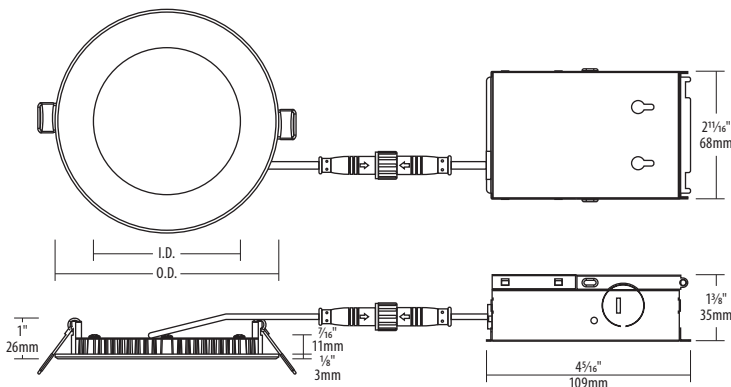


Size	O.D.	I.D.
SLM4	4 1/16" (119.5mm)	3 3/32" (78.5mm)
SLM4H	4 3/16" (122mm)	3 1/8" (79mm)

CCT	Lumens	
	SLM4	SLM4H
2700 K	590	850
3000 K	630	880
3500 K	660	920
4000 K	680	940
5000 K	660	920



## Ordering Guide

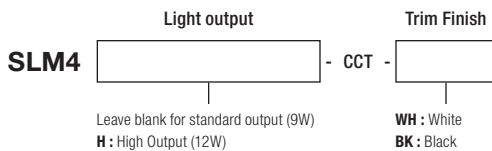

**Notes:**  
Accessories are sold separately. For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

## Accessories



### SLM4-XLRING-BK

Extra large trim ring for SLM4-CCT, metal, black.



### SLM4-XLRING-WH

Extra large trim ring for SLM4-CCT, metal, white.



### SLM4P-XLRING-BK

Extra large trim ring for SLM4H-CCT, metal, black.



### SLM4P-XLRING-WH

Extra large trim ring for SLM4H-CCT, metal, white.



### P-4020

4¼" Round pre-mounting plate with driver attachment clip, for 4" SlimLED fixtures.



### P-NCMK-1

Hanger bar kit. Includes hanger bars, brackets and screws.



### VBE-1

Vapour barrier extender. For use in new construction applications.



### VBE-2

Vapour barrier extender. For use in remodel applications.



### VBE-3

Vapour barrier extender. For use in remodel applications.



### VBE-5

Vapour barrier extender. For use in new construction applications.



### LC-CRTL-3WAY-1

OnCloud Smart Wi-Fi 3-way switch. Suitable for 3-way or 4-way switch applications.



### LC-CRTL-DIM-1

OnCloud Smart Wi-Fi dimmer. Features an ON/OFF press and a 7 level touch slider.