



Series Spec Sheet

LED TAPE KIT

EASY DIY

Stanpro's low voltage LED TAPE KITS are designed to enhance any space with a dramatic statement of color. Add ambiance and character to any setting.

It provides a great brightness either for color changing RGB version or cool and warm white colors and with its ease of installation, it can be used in a multitude of applications both indoor and outdoor!

View our full collection of LED strip tapes and extrusion offerings in our [brochure](#).

FEATURES AND SPECIFICATIONS

• Construction

Physical Characteristics

- Reel length 16.4' (5m)
- 12 V
- 9 LED/ft, 30 LED/m, 150 LED/reel
- Included in the kit:
 - 1 Tape light
 - 1 plug-in driver
 - 1 RGB remote control (for RGB kit only)
 - 2 End caps

Mounting

- 3M Adhesive backing for an easy installation to smooth surfaces
- Variety of fixing accessories: RGB connector, connector and mounting clips
- No soldering required with our variety of connectors and accessories available
- Additional driver can be ordered separately

• Performance data

- DC, Constant voltage
- Estimated lifespan of 30 000 hours to L70
- Can be installed outside
- Cannot be directly exposed to water or weather

Color temperatures available:

RGB

- Total reel wattage 27 W
- Dimming is only available using the "Brightness +/-" option on the remote control.

Warm white (2 700 K) and Cool white (5 000 K)

- Total reel wattage 27 W

3^{yrs}
warranty



OVERVIEW

Light source	LED
Watts (W)	1.7
Lumen output (lm)	1 980
Efficacy (lm/W)	55
Color temperature (K)	RGB, 2 700, 5 000

QUICK SHIP AND TECHNICAL SPECIFICATION TABLE 

TAPE KITS

Order code	Model number	Watts		Volts (VAC)	Color temp. (K) ¹	Lumen output (lm) ²		Life L70 (hrs) ³	Dimming capability (Yes/No)	Number of LED chips		Master case qty
		(per ft.)	(per m.)			(per ft.)	(per m.)			(per ft.)	(per m.)	
REEL 16.4' (5 m)												
61953	LED/TAPE/16.4'/5050/RGB KIT/12V/50M/STD	1.6	5.4	12	RGB	-	-	30 000	Yes	9	30	20
61954	LED/TAPE/16.4'/5050/WW KIT/12V/50M/STD	1.7	5.6	12	2 700	123	396	30 000	No	9	30	20
61955	LED/TAPE/16.4'/5050/CW KIT/12V/50M/STD	1.7	5.6	12	5 000	123	396	30 000	No	9	30	20

¹ Typical color temperature range: +/- 5 %.

² Lumen values are derived from photometric testing. Initial lumens range: +/- 10 %.

³ Life hours are derived from IESNA LM-80-08 testing report and projected per IESNA TM-21-11 extrapolations.

INCLUDED IN THE BOX



1 RGB remote control (for RGB kit only)



1 Plug-in driver



2 End caps




1 Tape light 16.4' (5m)

LED DRIVERS (additional drivers can be ordered separately)

Order code	Model number	Type	Output power	Output volts (V DC)	Length		Master case qty
			(W)		(per ft.)	(per m.)	
Plug-in - Non-Dimmable							
62265	LED/TAPE/36W/12V/WW+CW/PS/ND/STD	Low Voltage	36	12	6.56	2	50
62266	LED/TAPE/36W/12V/RGB/PS/ND/STD	Low Voltage	36	12	6.56	2	50


ACCESSORIES (order separately)

Order code	Description	Type	Figure refer to pics	Quantity per pack	Case qty (master)
61956	LED/TAPE/RGB/CONNECTOR/STD	RGB Connector	A	10	50
61957	LED/TAPE/WW+CW/CONNECTOR/STD	Connector	B	10	100
62017	LED/10PCS TAPE LIGHT 12V MOUNTING CLIPS	Mounting clips	C	10	100

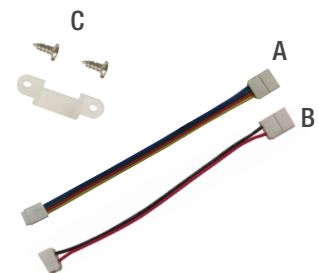


Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions. All products are subject to change or may be discontinued any time without notice.


DIMENSIONS

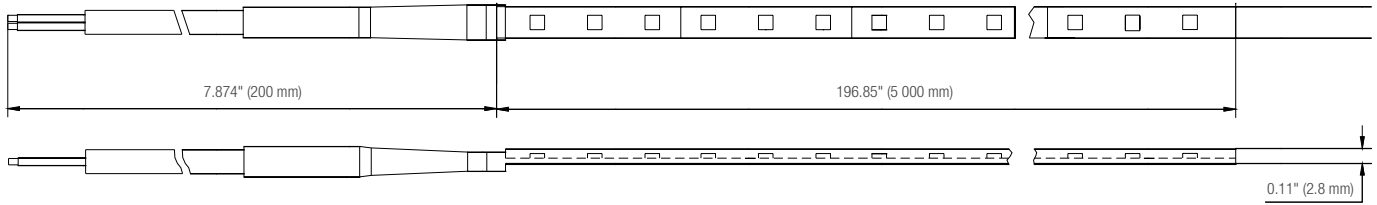

61953

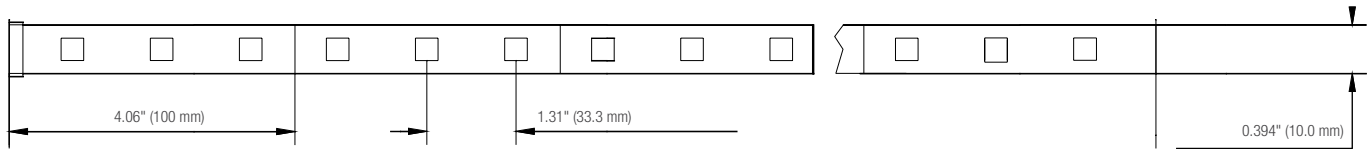

61954 - 61955

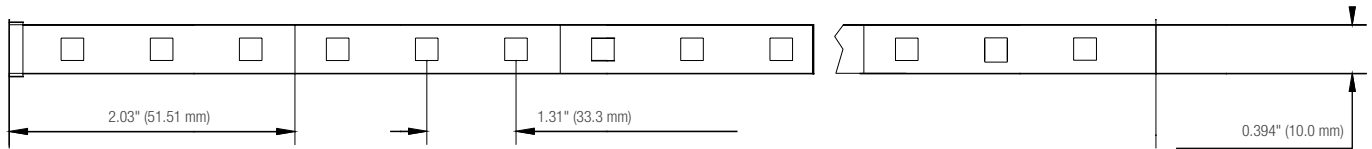

Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions.
 All products are subject to change or may be discontinued any time without notice.