



LED Recessed Troffer

Transform your lighting into an exquisite balance of refined appearance and superior efficiency.


Our wide variety of quality recessed troffers is perfect for any commercial application. They are perfectly suited for offices, as the well distributed light enhances productivity and reduces fatigue.




LED Panel

Boasting a universal driver that can operate from 100 V to 347 V and high lumen packages, the STANDARD commercial grade panels are the perfect solution to meet required light levels in any application. Offering an extended warranty of 10 years is a testament to the quality of the edge-lit panels STANDARD offers.

- Consistent even dimming you can depend on
- Designed to fit seamlessly into existing T-bar systems or alternatively can be surface-mounted or suspended for a unique look
- Ideal replacement for traditional fluorescent fixtures
- Premium quality components ensure optimal heat dissipation, consistent colour and longevity
- Optical system utilizes a unique combination of reflective and refractive optical components to achieve a uniform, comfortable appearance.

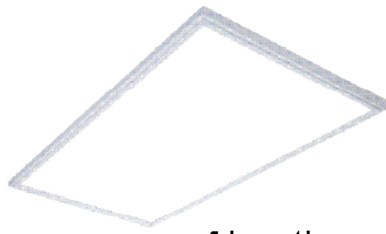

1' x 4'

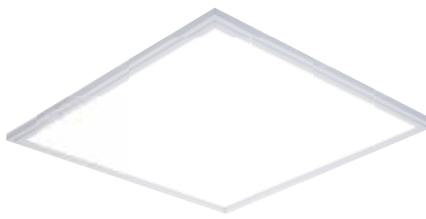


2' x 2'



2' x 4'

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Case qty (master)
1' x 4'								
66978 ¹	LPAN/S2/1X4/120-347V-DIM/40W/30K/STD	40	100-347	3 000	4 064	80	63 000	2
67211	PAN1X4/100-347/40W/35K/PRO/STD	40	100-347	3 500	4 723	80	60 000	2
67212	PAN1X4/100-347/40W/40K/PRO/STD	40	100-347	4 000	4 776	80	60 000	2
66089	LPAN/S2/1X4/120-347V-DIM/40W/50K/STD	40	100-347	5 000	4 731	80	60 000	2
2' x 2'								
66979 ¹	LPAN/S2/2X2/120-347V-DIM/40W/30K/STD	40	100-347	3 000	3 879	80	63 000	4
67214	PAN2X2/100-347/40W/35K/PRO/STD	40	100-347	3 500	4 891	80	60 000	4
65543	LPAN/S2/2X2/120-347V-DIM/40W/40K/STD	40	100-347	4 000	4 926	80	60 000	4
67216	PAN2X2/100-347/40W/50K/PRO/STD	40	100-347	5 000	5 026	80	60 000	4
2' x 4'								
66980 ¹	LPAN/S2/2X4/120-347V-DIM/50W/30K/STD	50	100-347	3 000	5 114	80	63 000	2
67217	PAN2X4/100-347/50W/35K/PRO/STD	50	100-347	3 500	5 804	80	60 000	2
65546	LPAN/S2/2X4/120-347V-DIM/50W/40K/STD	50	100-347	4 000	5 607	80	60 000	2
67219	PAN2X4/100-347/50W/50K/PRO/STD	50	100-347	5 000	6 024	80	60 000	2

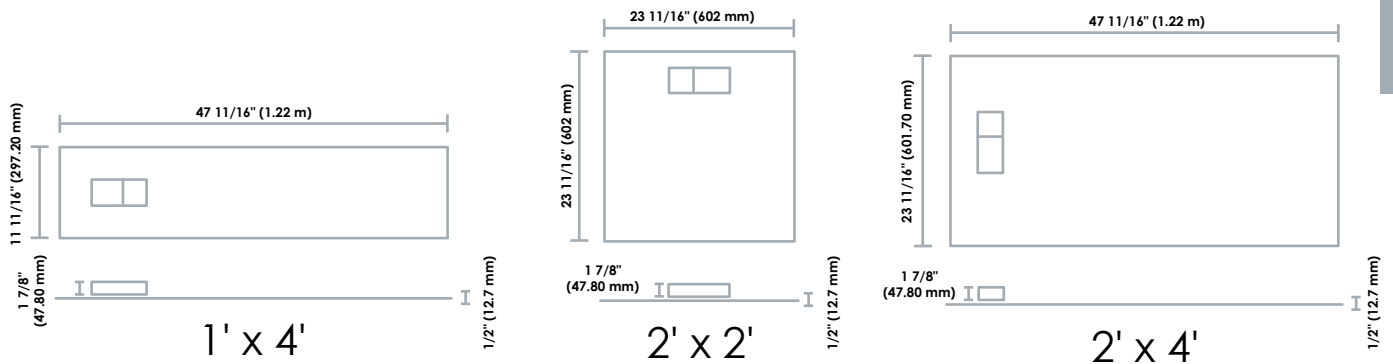

Accessories

Order code	Description	Type
64825	LPAN/ACC/2X2/SMK/STD	Surface mount kit
64826	LPAN/ACC/1X4/SMK/STD	Surface mount kit
64827	LPAN/ACC/2X4/SMK/STD	Surface mount kit
64828	LPAN/ACC/2X2/SUSPENSION/STD	Suspension cable
64829	LPAN/ACC/1X4_2X4/SUSPENSION/STD	Suspension cable
63490	DRYWALL KIT FOR 1X4 FRT/STD	Drywall kit
63491	DRYWALL KIT FOR 2X4 FRT/STD	Drywall kit



Lumen values are derived from photometric testing.
For a complete list of compatible dimmers and DLC qualified products, please visit www.standardpro.com
¹ DLC Standard




LED Center Basket


The LRCB series of luminaires has an indirect center-diffuser that provides an optimal modern alternative to traditional fluorescent recessed luminaires. Their modern sleek look provides a smooth and visually comfortable lighting that eliminates surface shadows.




Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Case qty (master)
1' x 4'								
65550	LRCB/S2/1X4/120-277V-DIM/35W/35K/STD	35	120-277	3 500	4 293	80	100 000	1
65551	LRCB/S2/1X4/120-277V-DIM/35W/40K/STD	35	120-277	4 000	4 515	80	100 000	1
65552	LRCB/S2/1X4/120-277V-DIM/35W/50K/STD	35	120-277	5 000	4 550	80	100 000	1
2' x 2'								
65553	LRCB/S2/2X2/120-277V-DIM/35W/35K/STD	35	120-277	3 500	4 242	80	100 000	1
65554	LRCB/S2/2X2/120-277V-DIM/35W/40K/STD	35	120-277	4 000	4 410	80	100 000	1
65555	LRCB/S2/2X2/120-277V-DIM/35W/50K/STD	35	120-277	5 000	4 445	80	100 000	1
2' x 4'								
65556	LRCB/2X4/S2/120-277V-DIM/46W/35K/STD	46	120-277	3 500	5 730	80	100 000	1
65557	LRCB/2X4/S2/120-277V-DIM/46W/40K/STD	46	120-277	4 000	5 796	80	100 000	1
65558	LRCB/2X4/S2/120-277V-DIM/46W/50K/STD	46	120-277	5 000	5 842	80	100 000	1

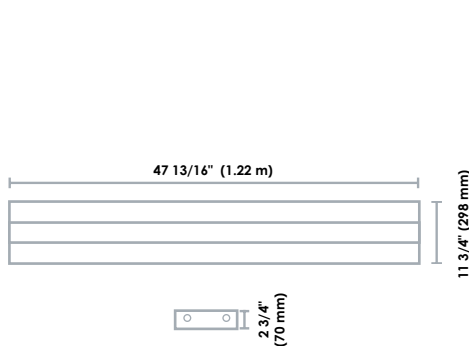

1' x 4'

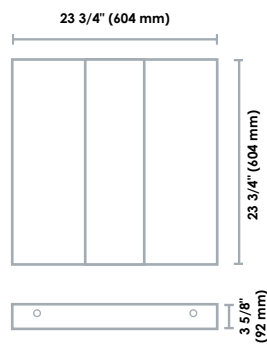

2' x 2'

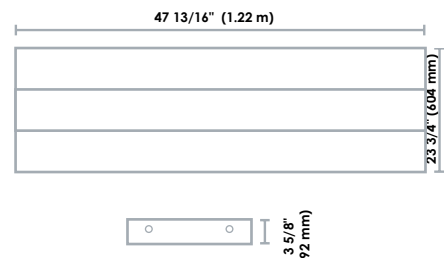

2' x 4'

Accessories

Order code	Description	Type
63490	DRYWALL KIT FOR 1X4 FRT/STD	Drywall kit
63491	DRYWALL KIT FOR 2X4 FRT/STD	Drywall kit



Lumen values are derived from photometric testing
For a complete list of compatible dimmers and DLC qualified products, please visit www.standardpro.com

STANDARD © 2019 STANDARD Products Inc. All Rights Reserved.
www.standardpro.com Rev. March 18, 2019.




LED RetroKit

Use the conversion kit to modernize your existing fluorescent luminaires to convert and upgrade to LED. Improve the look of your ceiling with its architectural design without the need to break in the ceiling. Achieve instant savings by reducing installation and maintenance costs.

Installation can be done in less than 5 minutes!



Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Case qty (master)
2' x 2'								
65362	LRT/RETRO/2X2/120-277V-DIM/40W/40/STD	40	120-277	4 000	4 708	85	133 000	4
2' x 4'								
65363	LRT/RETRO/2X4/120-277V-DIM/50W/40/STD	50	120-277	4 000	6 047	85	133 000	4

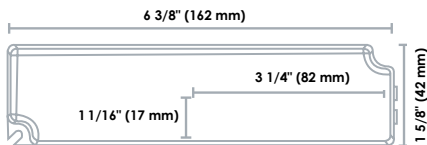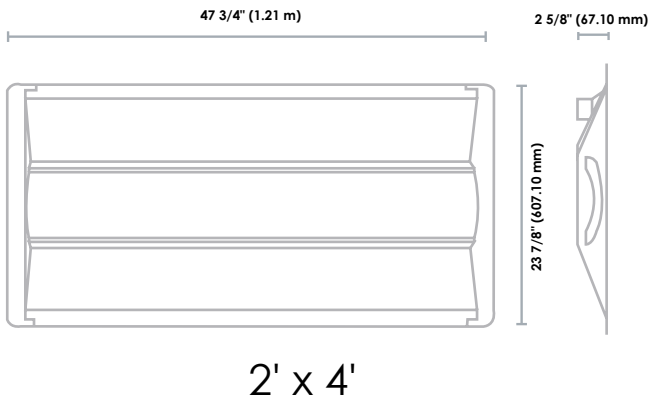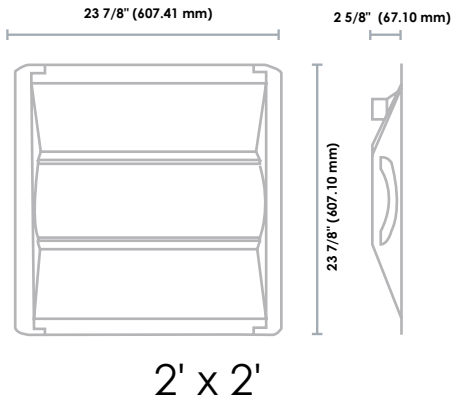

LED Driver



Lumen values are derived from photometric testing
For a complete list of compatible dimmers and DLC qualified products, please visit www.standardpro.com