

Power Hook for Industrial High Bay Luminaires

Receptacle and Hook and Loop

UNILETS™ for Use with Threaded Rigid Metal Conduit and IMC.

NEC/CEC: Suitable for use in Ordinary (Unclassified) Locations

Applications

- Designed for suspension of lighting fixtures.

Features

- Permit quick disconnect and removal of fixture for maintenance.
- Available in pendant or feed-thru.
- Available with matching cord set.

Standard Materials

- Malleable iron with steel cover
- Screws: stainless steel

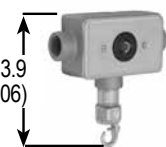
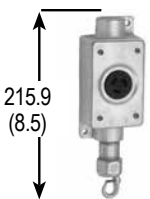
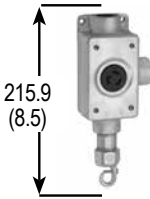
Standard Finishes

- Malleable iron parts: triple coat — (1) zinc electroplate, (2) chromate, and (3) epoxy powder coat
- Steel parts: zinc electroplate

NEC/CEC Certifications and Compliances

- UL Standard: UL 57
- CSA Standard: C22.2 No. 9, C22.2 No. 250

Receptacle Hangers

	Support Weight in kg (lbs)	Conduit Hub Size (Inches)	Voltage	Plug	Weight in kg (lbs)	Catalog Number
GHPHP — Pendant — Furnished with assembled FS box, EFHM safety hook, receptacle, and steel cover						
	40 kg (90 lbs)	3/4	120	L5-15P	1.19 (2.51)	GHPHP12
		3/4	208, 240	L6-15P	0.95 (2.10)	GHPHP24
		3/4	277	L7-15P	2.08 (4.58)	GHPHP27
		3/4	347	L37-20P	1.27 (2.80)	GHPHP34
		3/4	480	L8-20P	1.27 (2.80)	GHPHP48
		3/4	600	L9-20P	1.27 (2.80)	GHPHP60
GHPHT — Feed-Thru — Furnished with assembled FS box, EFHM safety hook, receptacle, and steel cover						
	40 kg (90 lbs)	3/4	120	L5-15P	1.22 (2.69)	GHPHT12
		3/4	208, 240	L6-15P	1.39 (3.08)	GHPHT24
		3/4	277	L7-15P	1.47 (3.23)	GHPHT27
		3/4	347	L37-20P	1.36 (3.00)	GHPHT34
		3/4	480	L8-20P	1.36 (3.00)	GHPHT48
		3/4	600	L9-20P	1.36 (3.00)	GHPHT60
FHC — Pendant — Furnished with assembled FS box, EFHM safety hook, receptacle, and steel cover						
	40 kg (90 lbs)	3/4	120	15	1.42 (3.13)	FHC75-1512C
		3/4	208	15	1.42 (3.13)	FHC75-1528C
		3/4	240	15	1.42 (3.13)	FHC75-1525C
		3/4	277	15	1.42 (3.13)	FHC75-1527C
		3/4	347	20	1.42 (3.13)	FHC75-2034C
		3/4	480	20	1.42 (3.13)	FHC75-2048C
		3/4	600	20	1.42 (3.13)	FHC75-2060C
FHCT — Feed-Thru —Furnished with assembled FS box, EFHM safety hook, receptacle, and steel cover						
	40 kg (90 lbs)	3/4	120	15	1.62 (3.56)	FHCT75-1512C
		3/4	208	15	1.62 (3.56)	FHCT75-1528C
		3/4	240	15	1.62 (3.56)	FHCT75-1525C
		3/4	277	15	1.62 (3.56)	FHCT75-1527C
		3/4	347	20	1.62 (3.56)	FHCT75-2034C
		3/4	480	20	1.62 (3.56)	FHCT75-2048C
		3/4	600	20	1.62 (3.56)	FHCT75-2060C

Power Hook for Industrial High Bay Luminaires

Receptacle and Hook and Loop
UNILETS™ for Use with Threaded Rigid Metal Conduit and IMC.

NEC/CEC: Suitable for use in Ordinary (Unclassified) Locations

Cord Sets — With Loop — 1.21 m (4 ft) Cord

Supplied with 600 V, +90°C (+194 °F) 3 conductor No. 16 SOOW cable, locking plug and 3/4" FHLM loop

	Voltage	Amperes	Weight in kg (lbs)	Catalog Number
	120	15	0.48 (1.06)	G-HCPL-4-12
	208, 240	15	0.59 (1.30)	G-HCPL-4-24
	277	15	0.46 (1.02)	G-HCPL-4-27
	347	20	0.46 (1.02)	G-HCPL-4-34
	480	20	0.46 (1.02)	G-HCPL-4-48
	600	20	0.46 (1.02)	G-HCPL-4-60

Fuse and Cartridge

Cartridges are furnished complete with two 254 mm (10") long high temperature wire leads and 600 Volt fuse

	Amperes	Weight in kg (lbs)	Catalog Number
	6	0.07 (0.15)	G-F6
	30	0.11 (0.25)	G-F30