


Eaton C25GNF290A

Catalog Number: C25GNF290A

Eaton definite purpose contactor, Quick, 360A, 110-120 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and three-pole, 360A, Contactor, Three-pole, 360A, three-pole, 360A, Box lugs (posidrive setscrew), Non-reversing

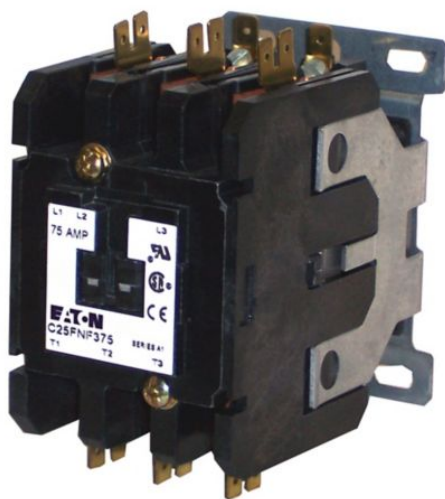

General specifications

Product Name	Catalog Number
Eaton definite purpose contactor	C25GNF290A
UPC	Product Length/Depth
782114100165	3.97 in
Product Height	Product Width
3.75 in	2.63 in
Product Weight	Warranty
2.66 lb	Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.
Compliances	Certifications
RoHS Compliant CE Marked	UL Listed file E1491 (Guide Number NLDX2) CSA Certified UL Recognized

defaultTaxonomyAttributeLabel

Accessories

Mounting plate

Number Of Poles

Three-pole

Options

Individual pkg.

Type

Non-reversing

Auxiliary contacts

Quick connect

Coil

208/240 Vac, 50/60 Hz

Coil voltage

110-120 Vac, 50/60 Hz

Enclosure

Open with metal mounting plate

Frame size

15-50 A, two-pole and three-pole

Model

Contactors

Series

F1

Terminals

Power terminals: box lugs posisetscrew and quick connect

Connection

Quick

Resources

Catalogs

Eaton's Volume 5—Motor Control and Protection

Drawings

C25GNF2 3D Inventor

C25GNF2 AutoCAD 2D Footprint (mm)

C25GNF2 3D Model Xchange

C25GNF2 AutoCAD 2D Footprint

C25GNF2 2D PDF

C25GNF2 2D Drawing Xchange

Specifications and datasheets

Eaton Specification Sheet - C25GNF290A



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)