


Eaton C25BNB240A

Catalog Number: C25BNB240A

Eaton definite purpose contactor, Mounting plate, Quick, 30A, Quick connect (side-by-side), 24 Vac, 50/60 Hz, Open with metal mounting plate, Compact, two-pole, 30A, Contactor, Two-pole, 50 pc./pkg., F1, Binding head screw, Non-reversing

General specifications

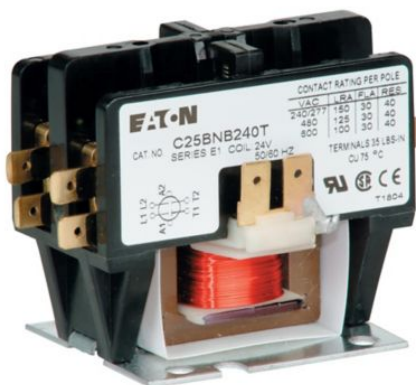

Product Name	Catalog Number
Eaton definite purpose contactor	C25BNB240A
UPC	Product Length/Depth
786685116075	2.32 in
Product Height	Product Width
3.19 in	1.97 in
Product Weight	Warranty
0.568 lb	1 year
Compliances	Certifications
RoHS Compliant	UL Recognized CSA Certified

defaultTaxonomyAttributeLabel

Amperage Rating

40A

Number Of Poles

Two-pole

Type

Non-reversing

Coil

110-120 Vac, 50/60 Hz

Enclosure

Open with metal mounting plate

Frame size

Compact, two-pole

Inductive full load

40 A

Model

Contactors

Resistive load

50 A

Terminals

Binding head screw and quick connect terminals (side-by-side)

Connection

Quick

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[C25BNB 3D Model Xchange](#)

[C25BNB 2D PDF](#)

[C25BNB AutoCAD 2D Footprint](#)

[C25BNB AutoCAD 2D Footprint \(mm\)](#)

[C25BNB 3D Inventor](#)

[C25BNB 2D Drawing Xchange](#)

Specifications and datasheets

[Quick Selector - Definite Purpose Contactors](#)

[Eaton Specification Sheet - C25BNB240A](#)