

# Scope

There are moments when you want the ability to direct light as you please. With our LED Gimbal recessed fixture, this has now become a reality with the easiest of installations.

**UPGRADE**  WET   **IC** RATED **JA8** CERTIFIED

 30° SWIVEL/DIRECTIONAL  AIR TIGHT  2700k 3000k 3500k 4000k 5000k COLOR TEMPERATURE



Model	Size	Watts	Delivered lumens	LED lumens	CRI	Color °T	Voltage
<b>GMB2-CC</b>	2"	8 W	725 lm	900 lm	90	2700, 3000, 3500, 4000, 5000 K	120 V
<b>LEDDOWNG3-CC</b>	3"	8 W	680 lm	750 lm			
<b>LEDDOWNG4-CC</b>	4"	8 W	680 lm	750 lm			
<b>GMB4-CC</b>	4"	11 W	810 lm	1000 lm			

### Specifications

Every fixture includes a junction box with integrated dimmable driver  
 Can be daisy chained (3" and 4" models only)  
 Superior LED performance and lifespan  
 30° tilting, 360° rotation  
 Minimal heat emission  
 Aluminum construction  
 Switch-selectable CCT: 2700K/3000 K/3500 K/4000 K/5000 K  
 Low profile  
 40° beam spread  
 IC certification (suitable for direct contact with insulation)  
 Air-tight certified as per ASTM E283-04  
 JA8 Certified  
 Suitable for wet locations  
 Refer to website for dimmer compatibility  
 Ideal operating temperature: -20° to 40° C  
 FT6 rated cable  
 5-year warranty

### Finish

- **BK** Black
- **SN** Satin Nickel (3" and 4" models only)
- **WH** White




### Accessories

- RFP-UNI**  
Universal rough-in plate (3" and 4" models)
- RFP-GMB2**  
Rough-in plate (2" model)
- RFP-46**  
Rough-in plate (3" and 4" models)

### Note




Other color °T, finishes, and voltage options are available but may require MOQ's and longer lead times. Please contact your DALI representative for more information.

  **GMB2-CC**

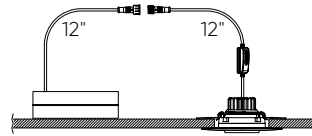




4-1/16" x 2" x 2"

 **LEDDOWNG3-CC**

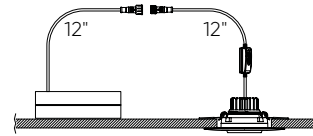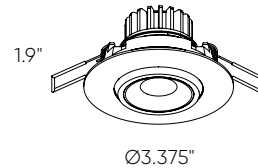




3-7/8" x 2-3/8" x 1-5/8"

 **LEDDOWNG4-CC**

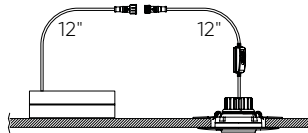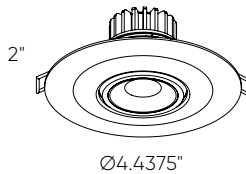

3-7/8" x 2-3/8" x 1-5/8"

 **GMB4-CC**

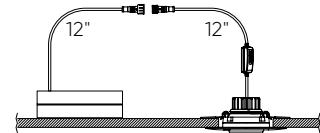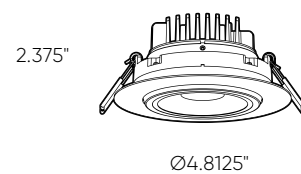

3-5/8" x 3-1/2" x 1-3/8"