



FR-LED-6-S15W-5CCT-FG

6" Round Fire Rated Floating Gimbal Recessed LED 5CCT 15W

Project: _____

Location: _____

Qty: _____

Notes: _____

DESCRIPTION

6" Round Fire Rated Floating Gimbal Recessed LED

The First Fully Adjustable Fire Rated Lighting Fixture



2 HOUR FIRE RATING
Tested to comply with UL 263, ASTM E119 & CAN ULC S101

FEATURES & BENEFITS



- 2 Hour Fire Rated** without additional housing or hardware
- Type IC & Air-Tight Rated** - No Housing Required
- Heat Resistant Steel Casing** provides up to 2 Hour Fire Protection
- Heavy Duty Steel Spring Clips** for easy installation
- 1" Spring Height** for installations on up to 2 x 5/8" drywall
- Plenum Rated Cable** for Commercial Installations
- 1 1/2" Thin** - Install in Limited Ceiling Spaces
- Driver Inside Connection Box** - No Junction Box Needed
- 5 CCT** User Selectable Light Colors
- CRI 90+** for True Color Rendering

| SPECIFICATION | |
|-----------------------|--|
| Applications | Multi-Family Residential, Basements & Commercial |
| Energy Used | 15 W |
| Color Temperature (K) | 2700 - 3000 - 3500 - 4000 - 5000 |
| Light Output (lm) | 1180 - 1270 - 1350 - 1370 - 1350 |
| Halogen Equivalent | 120 W |
| Beam Angle | 38° |
| CRI | 90+ |
| Driver Input | 120V AC 50/60 Hz |
| Dimming | TRIAC Dimmers 10% - 100% |
| Junction Box Volume | 9.69 cubic inches / Max 5 No 12 AWG or 8 No 14 AWG |
| Approved Location | Insulated Ceiling & Damp Locations |
| Cable | FT6 / CMP Plenum Rated |
| Air Tight & Type IC | Yes |
| Ambient Temperature | -4°F (-20°C) to +104°F (+40°C) |
| Projected Life | 70% Light Output at 50,000 Hours |
| Certification | cETLus |
| Fire Rating | UL 263-2011(R2022), STM E119-20 & CAN/ULC-S101-14 |
| Warranty | 3 Year |

DIMENSIONS ID 5 1/4" OD 6 7/8" Cut Out 5 1/2" to 6"

Fixture Thickness: 1 1/2"

120V Triac Dimmable Driver Included
5CCT switch on the driver

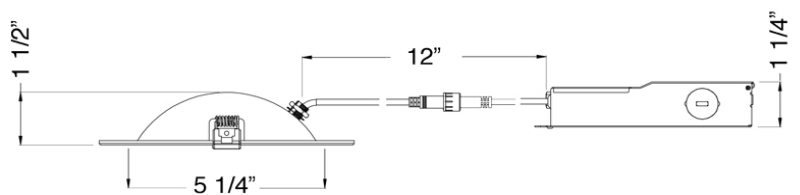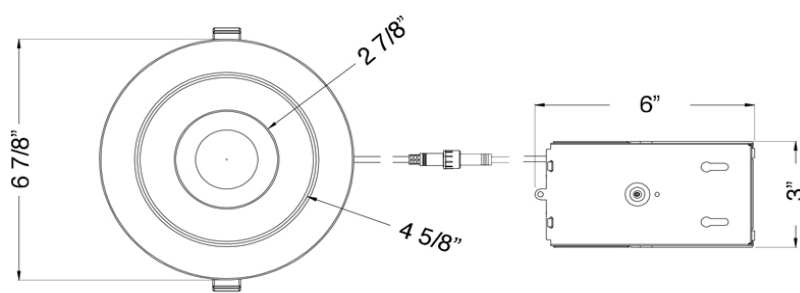

ACCESSORIES


Sold Separately

ORDERING GUIDE

| | CCT | Trim |
|---|------|-------|
| FR-LED-6-S15W-5CCT-FG-WH | 5CCT | White |
| 5CCT: 2700 - 3000 - 3500 - 4000 - 5000K | | |



Stock trim - White. Other Trim Colors Available By Custom Order

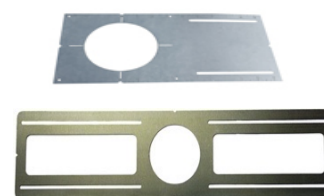


[13" Mounting Plate Flat model # MP6-2](#)



[26" Flat Rough-In Plates model # RIP6](#)



 [Flanged Plate with Hanger Bars - model # FRP6](#)



[Jumper Cable 10 ft. 5 CCT Model # FR-JC-5CCT-10](#)



[Goof Ring White OD 7 5/8" model # GR6](#)

Lotus LED Lights USA

250 H Street # 301, Blaine WA 98230 tel 360-200-5500
Hainesport NJ, Naples FL, Vancouver WA

www.LotusLEDLights.com

mailing addresses
warehouses

Lotus LED Lights CANADA

702 Chester Rd, Delta BC V3M 6J1 tel 604-538-3090
Delta BC, Mississauga ON