



LD4R



Type IC, Wet, Air-Tight & Open Plenum


DESCRIPTION

4" Round Deep Regressed LED - Elegant Design Without Glare
Commercial Grade Quality Built To Last

FEATURES & BENEFITS

- 5 single CCT, Dim to Warm, & 5CCT field selectable options
- 3 1/2" Deep - Install Where Ceiling Space Is Limited
- Armored Cable & Metal Connectors - Open Plenum Rated
- Driver Inside Connection Box with Romex Quick Connectors and Knock Outs - Fast Installation & No Junction Box Needed
- Type IC, Air-Tight & Wet Location - No Housing Required

DIMENSIONS ID 4" OD 4 7/8" Cut Out 4 1/4"

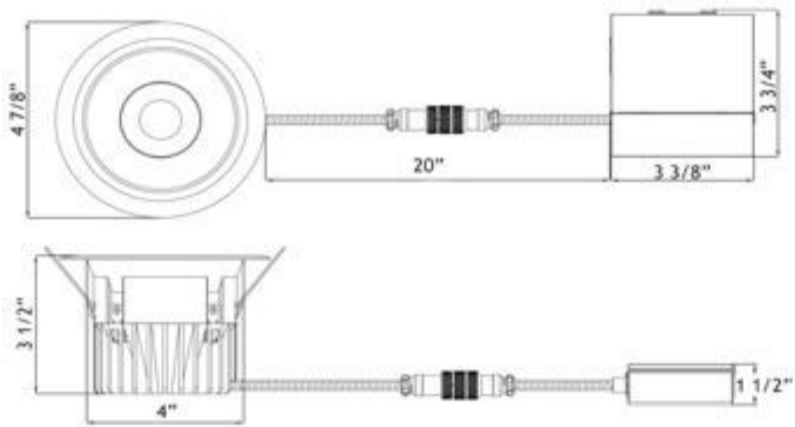

120V TRIAC Dimmable Driver Included Optional 120V-347V



0-10V Dimmable Driver
Order Separately as
[model # LLL-LD1535TR](#)

ORDERING GUIDE Example **LD4R-30K-4R-WR-WT**

	CCT	Reflector - Trim	Beam Angle
LD4R	- xxK	- 4R-xx-xx	
2700K	27K	4R-WR-WT	blank for 30°
3000K	30K	4R-SR-WT	-15D 15°
3500K	35K	4R-BR-WT	-60D 60°
4000K	40K	4R-BR-BT	
5000K	50K	4R-SR-BT	
DTW 30-20K	32K	4R-SR-ST	Dim To Warm 3000K to 2000K
DTW 30-18K	3018K	4R-ORB	Dim To Warm 3000K to 1800K
5CCT	5CCT		User selectable 27-30-35-40-50K

4" Round Deep Regressed LED Plenum Rated 15W

Project: _____
 Location: _____
 Model #: _____ Qty: _____
 Notes: _____

SPECIFICATION	
Applications	Recessed Ceiling Mount
Energy Used	15W
Color Temperature (K)	2700 3000 3500 4000 5000 DTW 30-20K DTW 30-18K
Light Output (lm)	1100 1200 1250 1300 1400 900 980
Beam Angle	30° (default), 15° & 60° optional
CRI	90 +
Default Driver Input	120V AC Triac Dimmable
Optional Driver Input	120V-347V AC 0-10V Dimmable
Junction Box Wire Capacity	Max 5 No 12 AWG or 8 No 14 AWG
Power Factor	0.98
Approved Location	Insulated Ceilings, Open Plenum, Wet Locations
IP Rating	IP 54
Air Tight	Yes
Ambient Temperature	-40°F (-40°C) to +104°F (+40°C)
Projected Life	70% Light Output at 50,000 Hours
Certification	cULus, Energy Star (except DTW & 5CCT), T24
Warranty	10 Year Residential / 5 Year Commercial

AVAILABLE TRIMS



White Reflector Silver Reflector Black Reflector Black Reflector Silver Reflector Silver Reflector Oil
 White Trim White Trim White Trim Black Trim Black Trim Silver Trim Rubbed Bronze
4R-WR-WT 4R-SR-WT 4R-BR-WT 4R-BR-BT 4R-SR-BT 4R-SR-ST ORB


ACCESSORIES

Sold Separately



- [26" Long Flat Rough-In Plate model # RIP4](#)
- [13" Long Flat Rough-In Plate model # MP4-2](#)
- [13" Long Flanged Rough-In Plate model # MP4](#)
- [4 1/8" Hole Flanged with Hanger Bars model # FRP4](#)
- [Armored Low Voltage Extension 10ft model # MEC10](#)
- [Goof Ring 5 3/4" White model # GR4 Black model # GR4-BK](#)

COMPLIANCE

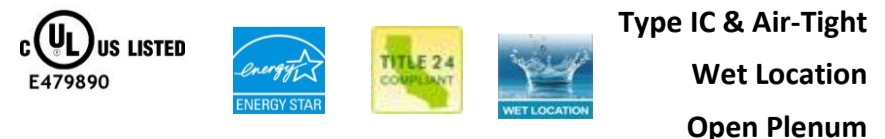

Type IC & Air-Tight
Wet Location
Open Plenum