



# LED-2-S5W-5CCT-FG

## 2" Round Floating Gimbal Recessed LED 5CCT 5W




### DESCRIPTION

2" LED Floating Gimbal  
Adjustable in any direction and easy to use  
Perfect for accent lighting

### FEATURES & BENEFITS

- 5 CCT Switchable - 2700-3000-3500-4000-5000K
- 1 1/4" Deep - Fits in 3/4" ceiling space (with driver remotely mounted)
- Type IC Rated - No Housing Required
- Driver Inside Connection Box - No Junction Box Needed
- White and Black trims in stock
- Damp Location & Airtight
- Ideal for slopped ceilings, soffits, wall washing, highlighting artwork, task lighting

**DIMENSIONS** ID 2 1/8" OD 3 1/2" Depth 1 1/4" Cut Out 2 3/4" to 3"

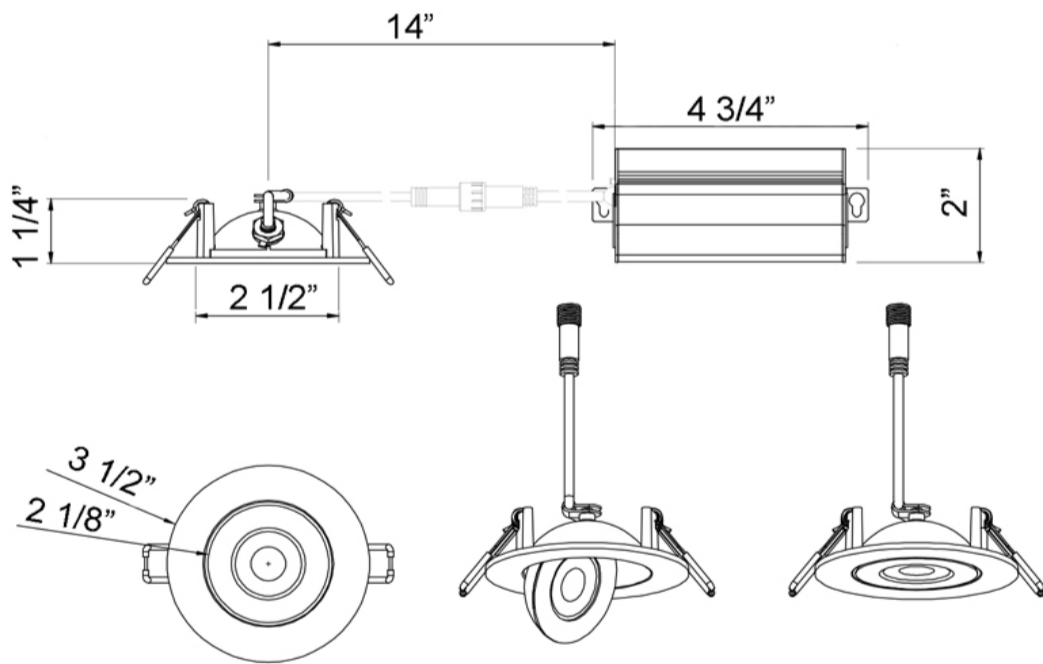

Project: \_\_\_\_\_


Location: \_\_\_\_\_

Model: \_\_\_\_\_ Qty: \_\_\_\_\_

Notes: \_\_\_\_\_

SPECIFICATION	
Applications	Slopped ceilings, soffits, wall washing, artwork
Energy Used	5 W
Color Temperature (K)	2700 - 3000 - 3500 - 4000 - 5000
Light Output (lm)	370 - 380 - 410 - 420 - 410
Halogen Equivalent	35 W
Beam Angle	38°
CRI	90+
Driver Input	120V AC
Dimmability	Triac Dimmable 100% - 10%
Junction Box Volume	6.53 in3 / 2 in 2 out 12AWG
Approved Location	Insulated Ceiling & Damp Locations
Air Tight	Yes
Ambient Temperature	-4° F (-20° C) to +104° F (+40° C)
Projected Life	70% Light Output at 50,000 Hours
Certification	cETLus
Warranty	3 Year

### Trim Options

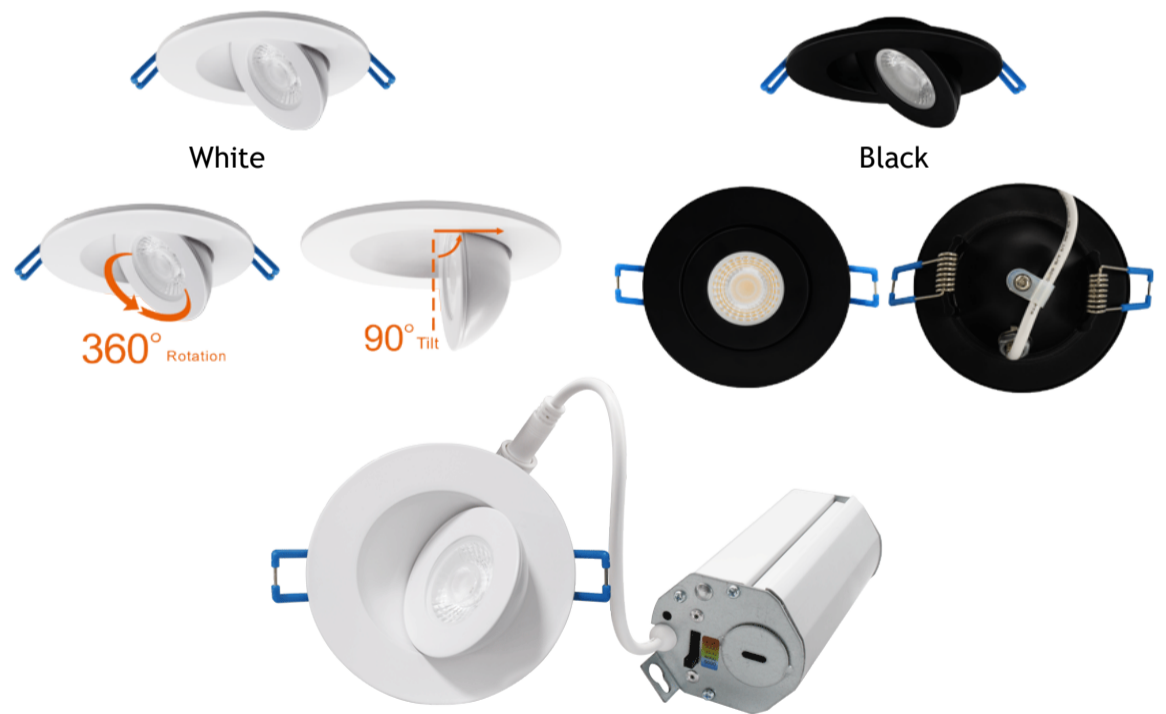

### ORDERING GUIDE

LED-2-S5W-5CCT-FG-WH  
LED-2-S5W-5CCT-FG-BK

[White Trim](#)  
[Black Trim](#)



### ACCESSORIES

Sold Separately



[Flanged Mounting Plate with bars model FRP212](#)

[Flat Mounting Plate model RIP212](#)

[Jumper Cables 10 ft model JC-5CCT-10](#)

### Lotus LED Lights USA

250 H Street # 301, Blaine WA 98230 tel 360-200-5500  
Hainesport NJ, Naples FL, Dallas TX, Vancouver WA

[www.LotusLEDLights.com](http://www.LotusLEDLights.com)

mailing addresses  
warehouses

### Lotus LED Lights CANADA

702 Chester Rd, Delta BC V3M 6J1 tel 604-538-3090  
Delta BC & Mississauga ON