



# 18-3 Shielded Non-Plenum

ETL listed for guaranteed performance  
Made in the USA

Part No.: 900913R

## Applications:

This document establishes the specifications for a three conductor shielded cable used for communication applications.

## Construction Details:


Number of Conductors: 3/C  
 Conductor: 18AWG Stranded Bare Copper  
 Insulation Material: Polyvinyl Chloride  
 Nominal Insulation Thickness: 0.008 in.  
 Nominal Insulation Diameter: 0.062 in.  
 Color Code: Black, White, Red  
 Shielding: Overall Aluminum/Polyester (100% coverage)  
 Drain: Stranded Tin Copper  
 Jacket Material: Polyvinyl Chloride  
 Nominal Jacket Thickness: 0.015 in.  
 Nominal Diameter: 0.200 in.  
 Surface Print: 3122598 CMR 18AWG C(ETL)US  
 FT4 + Sequential Footage Marking

## Electricals:

Suggested Working Voltage: 300 Volts, rms.

## Technical Details:

Temperature Rating	Operation: -20°C to +60°C
Nominal Weight:	26 lbs. / 1,000 feet

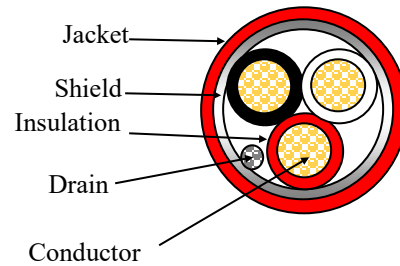

## Standards:

- NEC Article 800
- UL Subject 444
- CMR Type FT4

## Codes & Listings:

- C(ETL)US CMR FT4

## Preparation for Shipment:

The cable shall be packaged to preclude the inducement of damage due to handling and transportation, and shall be in accordance with the best commercial practices available. Shipping containers shall be constructed as to eliminate any possible damage to the cables due to shipment.




Issue Date: 06/15  
Revision: 1

All warranty information can be viewed at [WWW.REMEE.COM](http://WWW.REMEE.COM).

This product is RoHS compliant to directive 2002/95/EC .

PO Box 488 468 RT17A Florida, NY 10921  
 Customer Service: 800-431-3864 Fax: 845-651-4160 Website: [www.remee.com](http://www.remee.com)

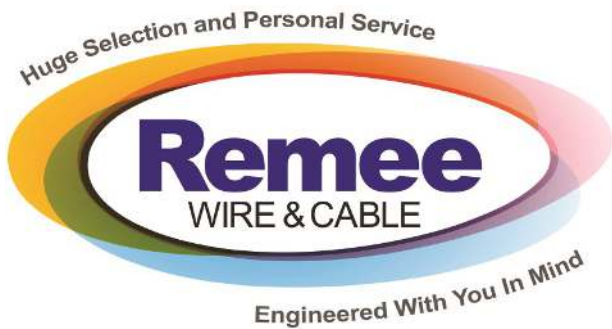

# 18-3 Shielded Non-Plenum

ETL listed for guaranteed performance  
Made in the USA

Part No.: 900913R

**Note:** While Remeë Products Corp. has made every reasonable effort to ensure the accuracy of the information in this document, Remeë Products Corp. does not guarantee that it is error-free, nor does Remeë Products Corp. make any other representation, warranty, or guarantee that the information is accurate, correct, reliable or current. Remeë Products Corp. reserves the right to make any adjustments to the information contained herein at any time without notice. Remeë Products Corp. expressly disclaims all implied warranties regarding the information contained herein, including but not limited to, any implied warranties of merchantability or fitness for particular purpose. The dimensions in this document are for reference purposes only and are subject to change without notice.

Your signature constitutes that you have read and agreed to this specification sheet and upon confirmation of your order; this item may be non-cancelable and non-returnable.

Signature: \_\_\_\_\_  
Company: \_\_\_\_\_  
Date: \_\_\_\_\_



Issue Date: 06/15  
Revision: 1

All warranty information can be viewed at [WWW.REMEE.COM](http://WWW.REMEE.COM).

This product is RoHS compliant to directive 2002/95/EC .

PO Box 488 468 RT17A Florida, NY 10921  
Customer Service: 800-431-3864 Fax: 845-651-4160 Website: [www.remee.com](http://www.remee.com)