





circular conduc. terminal TA4.3 4 x 4/0...500 kcmil for 4 cables; 3 units accessory for: 3VA55; 3VA65/3VA66

Model	
product brand name	SETRON
accessories	Wire connector
General technical data	
designation / of the terminal	TA4.3
type of electrical connection / with control wire tap	No
Connections according IEC	
connectable conductor cross-section	
• for copper cable / stranded / minimum	120 mm ²
• for copper cable / stranded / maximum	240 mm ²
stripped length	23.1 / 44.5 mm
tightening torque / when using copper cables	
• stranded	120 - 240 mm ² : 36.7 Nm
• finely stranded	185 mm ² : 36.7 Nm
Connections according UL	
permissible temperature / of connectable conductor / according to UL 486A-486B	90 °C
connectable conductor cross-section	
• for copper cable / stranded / minimum	4/0 AWG
• for copper cable / stranded / maximum	500 kcmil
• for aluminum cable / stranded / minimum	4/0 AWG
• for aluminum cable / stranded / maximum	500 kcmil
Certificates	
General Product Approval	



[Miscellaneous](#)



EMV	Marine / Shipping	other	Environment		
 RCM	 LRS	Confirmation	Miscellaneous	Miscellaneous	Environmental Confirmations

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9673-0JJ43>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9673-0JJ43>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9673-0JJ43

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

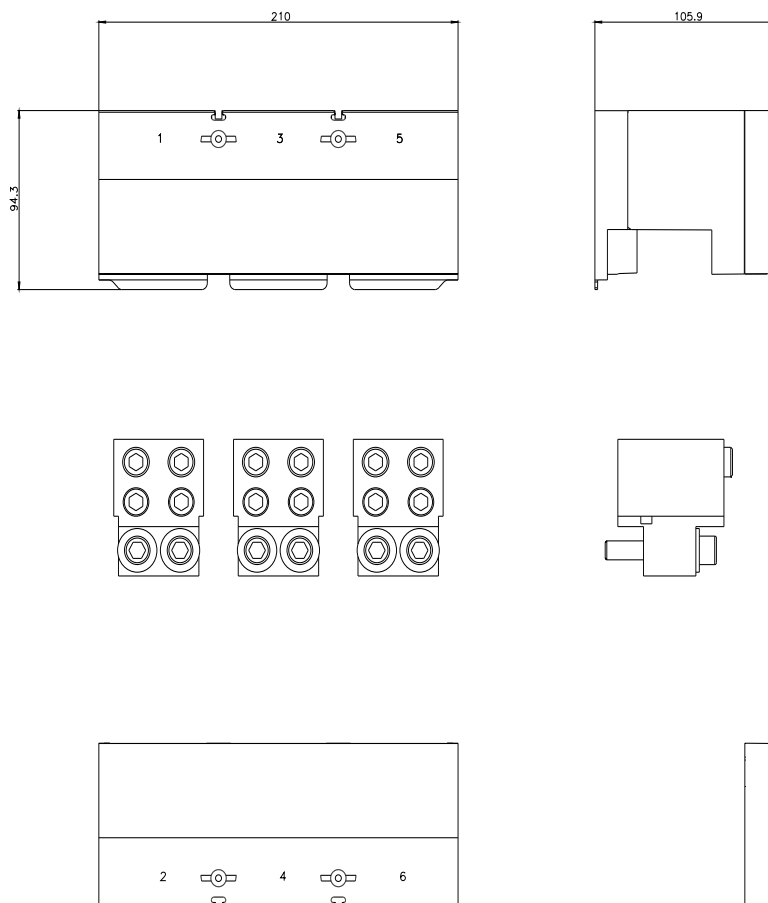

last modified:

10/25/2023 

