

**WLLED48-CCT**

Low Profile Wrap Light



NAME:	
TYPE:	
DATE:	
NOTES:	

**SPECIFICATIONS**


<b>WIRING:</b>	Hardwire only. Installs easily in traditional junction boxes (3" or 4"). Also features an internal junction box when the application requires linking multiple units in series.
<b>HOUSING DETAILS:</b>	Metal housing with durable plastic end caps. Mounts flush to a wall or ceiling.
<b>OPTICS:</b>	LED strip technology uses a light guided reflector to distribute light and optimize high level of delivered lumens. Integrated LED - no bulbs required. Maintenance free LED ceiling light.
<b>ELECTRICAL:</b>	Easily connected to a 120-277V power supply via provided UL recognized driver. Standard 120-277V, 0-10V dimmable driver. NON-IC and DAMP LOCATIONS rated. Certifications : This product is ETL and DLC 5.1 listed in USA and Canada.
<b>LENS:</b>	A light guide reflector in combination with a white acrylic frosted lens, provides an even light distribution.

<b>COLOR TEMPERATURE:</b>	3K - 4K - 5K
<b>CRI:</b>	80+
<b>LUMEN OUTPUT:</b>	4250 / 5000 / 6000 lumens
<b>DIMMABLE:</b>	Yes
<b>WATTS:</b>	36W / 42W / 52W selectable
<b>LED LIFE:</b>	50,000 hours
<b>WARRANTY:</b>	5 years
<b>VOLTAGE:</b>	120-277V
<b>HEIGHT:</b>	2.6" (6.60 cm)
<b>LENGTH:</b>	47.4" (120.40 cm)
<b>WIDTH:</b>	5.5" (13.97 cm)
<b>INTEGRATED MOTION SENSOR:</b>	No

**APPLICATIONS**

Low-profile LED wrap around with a frosted diffuser providing a widespread, uniform illumination. Ideal for many applications, including corridors, laundry rooms, kitchens, break rooms, utility work areas and stairways. Ideal for interior ceiling or wall installations in residential or commercial applications.

DIMENSIONS

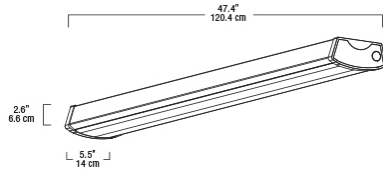

RATINGS



ORDERING GUIDE

**COBRAPLUS WRAP LIGHT SERIES**

Series	Length	Color Temperature	Finish
WLLED	48	CCT 3K-4K-5K	WH White
<b>Notes:</b>	Configure product using <b>BOLD</b> options: Ex: <b>WLLED48CCT-WH</b>		