



# CorePro Plastic (Dimmable) A-Shape Lamps

## 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

Dimmable A-shape lamps that offer over 25,000 hours lifetime. Title 20 listed lamps that can be sold in California and ideal for commercial spaces nationwide.

### Product data

General Information		Input Frequency	
Cap-Base	E26 [Single Contact Medium Screw]	Input Frequency	60 Hz
Nominal lifetime	15,000 hour(s)	Power Consumption	8.8 W
Switching Cycle	50,000	Lamp Current (Nom)	80 mA
Lighting Technology	LED	Wattage Equivalent	60 W
EU RoHS compliant	Yes	Starting Time (Nom)	0.5 s
		Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.7
		Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	927	T-Case Maximum (Nom)	90 °C
Beam Angle (Nom)	250 degree(s)		
Luminous Flux	800 lm	Controls and Dimming	
Color Designation	Warm White (WW)	Dimmable	Yes
Correlated Color Temperature (Nom)	2700 K		
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Mechanical and Housing	
Color Consistency	<4	Bulb Finish	Frosted
Color rendering index (CRI)	90	Bulb Material	Plastic
LLMF At End Of Nominal Lifetime (Nom)	70 %	Bulb Shape	A19
Operating and Electrical			
Line Frequency	60 Hz		

# CorePro Plastic (Dimmable) A-Shape Lamps

UL Wet/ damp/ dry location	Damp location
----------------------------	---------------

## Approval and Application

Energy Consumption kWh/1000 h	- kWh
Energy Certifications	Energy Star
T20 compliant	Yes

## Application Conditions


can it be used in closed luminaires	Yes
-------------------------------------	-----

## Product Data

Order product name	8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT
--------------------	---------------------------------------



Full product name	8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT
Order code	550434
Material Nr. (12NC)	929002036104
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677550431
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677550436

## Dimensional drawing

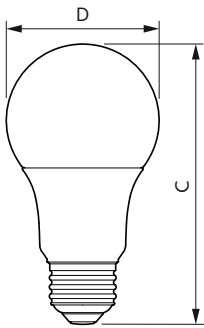

Product	D	C
8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT	62.5 mm	111.5 mm

## Photometric data

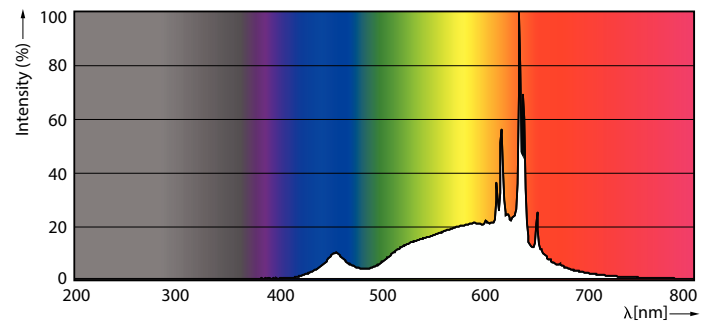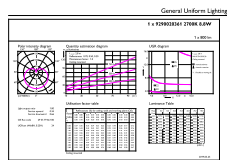


General uniform lighting - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

Spectral Power Distribution Colour - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

# CorePro Plastic (Dimmable) A-Shape Lamps

## Photometric data

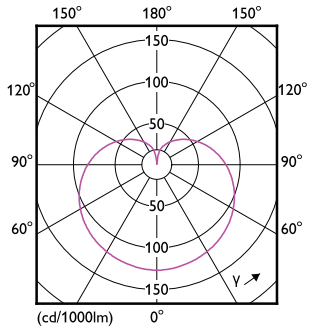

Light Distribution Diagram - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

## Lifetime



Life Expectancy Diagram - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT



Lumen Maintenance Diagram - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

