



TrueForce High Lumen PAR

33PAR38/PER/830/S15/DIM/120V 6/1FB

Philips LED TrueForce PAR high lumen lamps are the perfect transition from CDM lamps to LED.

Product data

General Information		Power Consumption	
Cap-Base	E26 [Single Contact Medium Screw]	Power Consumption	33 W
Nominal lifetime	25,000 hour(s)	Lamp Current (Nom)	300 mA
Switching Cycle	50,000	Wattage Equivalent	250 W
Lighting Technology	LED	Starting Time (Nom)	0.5 s
EU RoHS compliant	Yes	Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.95
		Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	830 [CCT of 3000K]	Ambient temperature range	-20 to +45 °C
Beam Angle (Nom)	15 degree(s)	T-Case Maximum (Nom)	90 °C
Luminous Flux	3,000 lm		
Luminous Intensity (Nom)	33,000 cd	Controls and Dimming	
Color Designation	White (WH)	Dimmable	Only with specific dimmers
Correlated Color Temperature (Nom)	3000 K		
Luminous Efficacy (rated) (Nom)	90 lm/W	Mechanical and Housing	
Color Consistency	<4	Bulb Finish	Clear
Color rendering index (CRI)	80	Bulb Material	Metal
LLMF At End Of Nominal Lifetime (Nom)	70 %	Bulb Shape	PAR38
		UL Wet/ damp/ dry location	Damp location
Operating and Electrical			
Line Frequency	50 to 60 Hz		
Input Frequency	50 to 60 Hz		

TrueForce High Lumen PAR

Approval and Application

Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	Energy Star
T20 compliant	N/A

Application Conditions


can it be used in closed luminaires	No
-------------------------------------	----

Product Data

Order product name	33PAR38/PER/830/S15/DIM/120V 6/1FB
--------------------	------------------------------------


Full product name	33PAR38/PER/830/S15/DIM/120V 6/1FB
Order code	534602
Material Nr. (12NC)	929001916804
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677534608
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677534603

Dimensional drawing

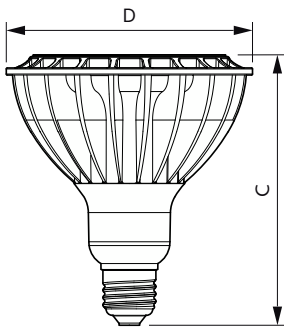


Product	D	C
33PAR38/PER/830/S15/DIM/120V 6/1FB	123 mm	133 mm

Photometric data

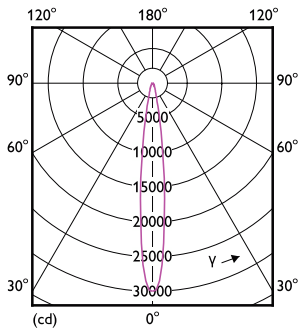


Light Distribution Diagram - 33PAR38/PER/830/S15/DIM/120V 6/1FB

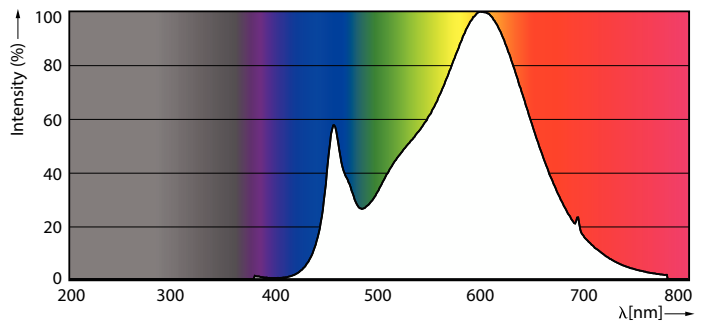

Spectral Power Distribution Colour - 33PAR38/PER/830/S15/DIM/120V 6/1FB

TrueForce High Lumen PAR


Photometric data

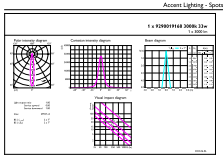


© 2024 Philips Lighting B.V. All rights reserved. Philips Lighting B.V. is a registered trademark of Koninklijke Philips N.V.

Accent Lighting Spots - 33PAR38/PER/830/S15/DIM/120V 6/1FB

Lifetime

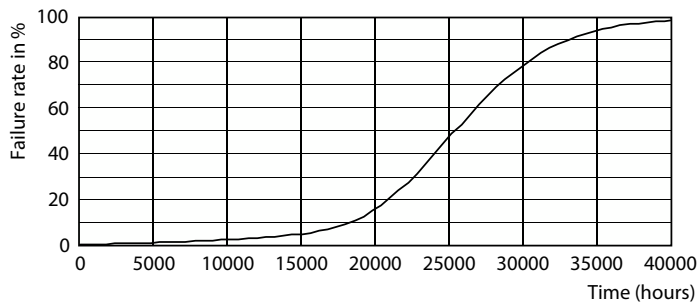

Life Expectancy Diagram - 33PAR38/PER/830/S15/DIM/120V 6/1FB

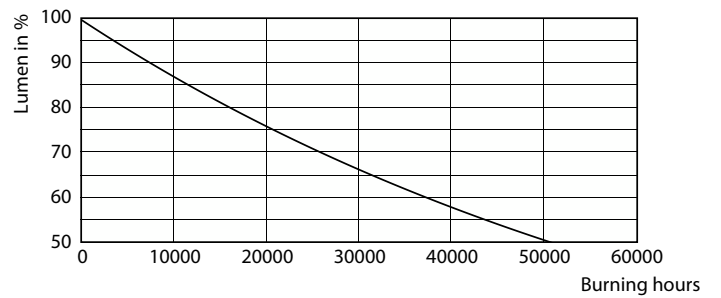

Lumen Maintenance Diagram - 33PAR38/PER/830/S15/DIM/120V 6/1FB

