



Switch Start Metal Halide Protected

MP1000/BU 6PK

An efficient, protected "O" rated lighting solution that is suitable for open-rated fixtures. Ideal for both indoor and outdoor applications.

Warnings and Safety

- R "WARNING: These lamps can cause serious skin burn and eye inflammation from short wave ultraviolet radiation if outer envelope of the lamp is broken or punctured. Do not use where people will remain for more than a few minutes unless adequate shielding or other safety precautions are used. Certain lamps that will automatically extinguish when the outer envelope is broken or punctured are commercially available." This lamp complies with FDA radiation performance standard 21 CFR subchapter J. (USA:21 CFR 1040.30 Canada: SOR/DORS/80-381)

Product data


General Information		Voltage (Nom)	
Cap-Base	EX39 [Exclusionary Mogul Screw]		263 V
Operating Position	H15 [Hanging +/-15D or Base Up (BU)]	Voltage (Nom)	263 V
Life to 50% Failures (Nom)	12,000 hour(s)		
Light Technical		Mechanical and Housing	
Color Code	635 [CCT of 3500K]	Bulb Finish	Clear
Color Designation	White (WH)	Bulb Material	Hard Glass
Chromaticity Coordinate X (Nom)	405	Bulb Shape	BT56
Chromaticity Coordinate Y (Nom)	390		
Correlated Color Temperature (Nom)	3500 K	Approval and Application	
Luminous Efficacy (rated) (Nom)	107 lm/W	Mercury (Hg) Content (Nom)	150 mg
Color rendering index (CRI)	65		
Operating and Electrical		Product Data	
Lamp Current (Nom)	4.1 A	Order product name	MP1000/BU 6PK
		Full product name	MP1000/BU 6PK
		Order code	281188
		Material Nr. (12NC)	928601179601

Switch Start Metal Halide Protected

Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677281182
Numerator - Packs per outer box	6

EAN/UPC - Case	50046677281187
----------------	----------------

Dimensional drawing

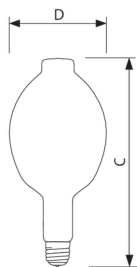

Product	D	C (max)
MP1000/BU 6PK	7 inch	15.375 inch

