



# LED PAR38

## 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

### Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	25,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
EU RoHS compliant	Yes

Light Technical	
Color Code	927 [CCT of 2700K]
Beam Angle (Nom)	40 degree(s)
Luminous Flux	900 lm
Luminous Intensity (Nom)	1,800 cd
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical	
Line Frequency	50 to 60 Hz
Input Frequency	50 to 60 Hz
Power Consumption	10 W
Lamp Current (Nom)	97 mA

Wattage Equivalent	90 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.9
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	70 °C

Controls and Dimming	
Dimmable	Only with specific dimmers

Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	PAR38

Approval and Application	
Suitable For Accent Lighting	Yes
Energy Certifications	Energy Star


Product Data	
Order product name	10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB

# LED PAR38

Full product name	10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB
Order code	567891
Material Nr. (12NC)	929003029004
Numerator - Quantity Per Pack	1



EAN/UPC - Product/Case	046677567897
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677567892

## Dimensional drawing

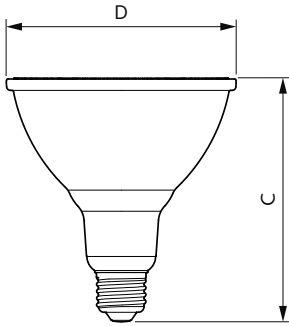


Product	D	C
10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB	122 mm	129 mm

## Photometric data

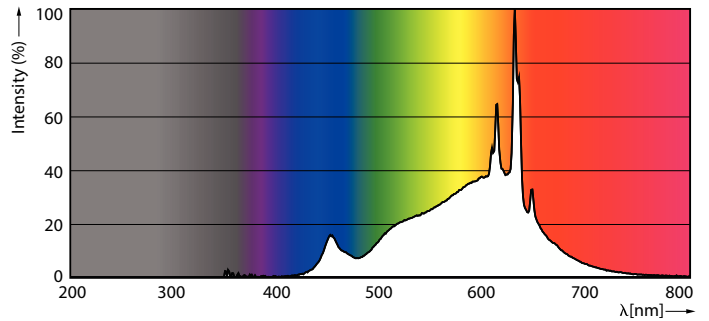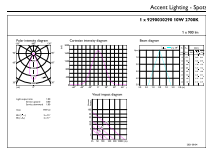

Accent Lighting Spots - 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB

Spectral Power Distribution Colour - 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB

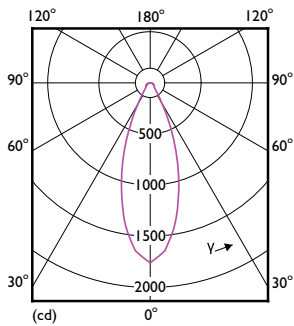

Light Distribution Diagram - 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB

# LED PAR38

## Lifetime



Life Expectancy Diagram - 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB

Lumen Maintenance Diagram - 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB

