



# Contractor-grade Plastic (Dimmable) A-Shape Lamps

## 14A19/CNG/850/FR/P/E26/D 4/4CT

Plastic A19 offering dimmability and a lifetime over 15,000 hours. Ideal for contractor-grade residential and multi-family spaces.

### Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	15,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
EU RoHS compliant	Yes

Light Technical	
Color Code	850 [CCT of 5000K]
Luminous Flux	1,600 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	114 lm/W
Color Consistency	<6
Color rendering index (CRI)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical	
Line Frequency	60 Hz
Input Frequency	60 Hz

Power Consumption	14 W
Lamp Current (Nom)	120 mA
Wattage Equivalent	100 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	120 V

Temperature	
Ambient temperature range	-20 °C to 45 °C
T-Case Maximum (Nom)	90 °C

Controls and Dimming	
Dimmable	Only with specific dimmers


Mechanical and Housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A19

# Contractor-grade Plastic (Dimmable) A-Shape Lamps

UL Wet/ damp/ dry location	Damp location
<b>Approval and Application</b>	
T20 compliant	No
<b>Application Conditions</b>	
can it be used in closed luminaires	Yes
<b>Product Data</b>	
Order product name	14A19/CNG/850/FR/P/E26/D 4/4CT



Full product name	14A19/CNG/850/FR/P/E26/D 4/4CT
Order code	581868
Material Nr. (12NC)	929003585304
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677581862
Numerator - Packs per outer box	4
EAN/UPC - Case	50046677581867

## Dimensional drawing

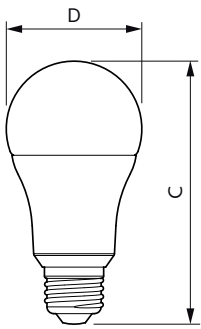

Product	D	C
14A19/CNG/850/FR/P/E26/D 4/4CT	60 mm	117 mm

## Photometric data

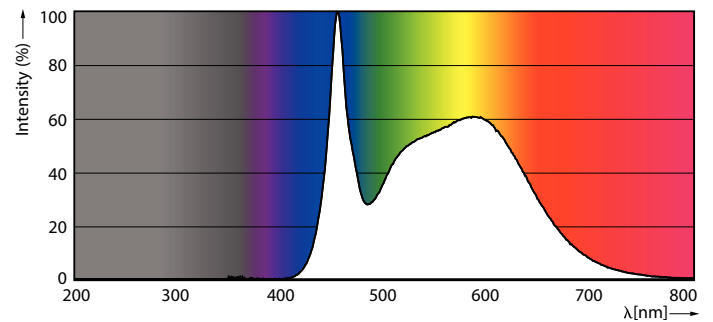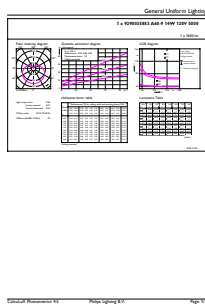


General uniform lighting - 14A19/CNG/850/FR/P/E26/D 4/4CT

Spectral Power Distribution Colour - 14A19/CNG/850/FR/P/E26/D 4/4CT

# Contractor-grade Plastic (Dimmable) A-Shape Lamps

## Photometric data

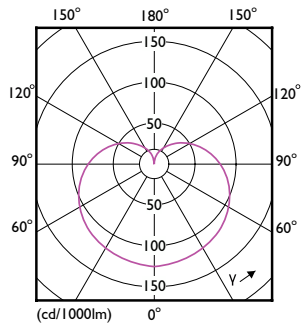


Light Distribution Diagram - 14A19/CNG/850/FR/P/E26/D 4/4CT

## Lifetime



Life Expectancy Diagram - 14A19/CNG/850/FR/P/E26/D 4/4CT

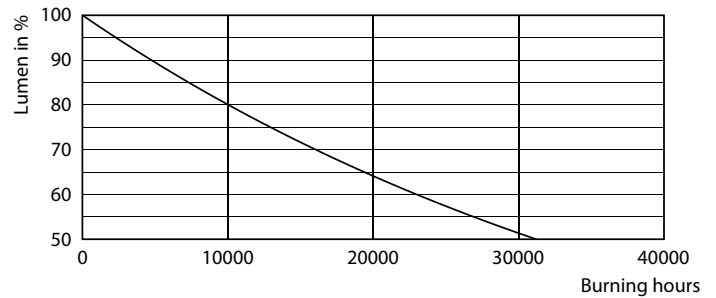

Lumen Maintenance Diagram - 14A19/CNG/850/FR/P/E26/D 4/4CT

