



# Circline

## FC12T9/DAYLIGHT DELUXE 12PK

T9 4-Pin Circular Fluorescent Lamps.


### Product data

General Information	
Cap-Base	G10Q [G10q]
Life to 50% Failures (Nom)	13,000 hour(s)
Light Technical	
Color Code	54
Luminous Flux	1,570 lm
Color Designation	Cool Daylight
Correlated Color Temperature (Nom)	6200 K
Color rendering index (CRI)	79
Operating and Electrical	
Power Consumption	31 W
Lamp Current (Nom)	0.43 A
Voltage (Nom)	84 V
Voltage (Nom)	84 V
Controls and Dimming	
Dimmable	No

Mechanical and Housing	
Bulb Shape	C-T29
Approval and Application	
Mercury (Hg) Content (Nom)	8.0 mg
Product Data	
Order product name	FC12T9/DAYLIGHT DELUXE 12PK
Full product name	FC12T9/DAYLIGHT DELUXE 12PK
Order code	928028605435
Material Nr. (12NC)	928028605435
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677262600
Numerator - Packs per outer box	12
EAN/UPC - Case	50046677262605

# Circline

## Dimensional drawing

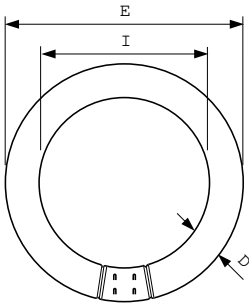

Product	D (max)	D (min)	E (min)	E (max)	I (min)	I (max)
FC12T9/DAYLIGHT	31.0 mm	26.2 mm	292.1 mm	304.8 mm	239.5 mm	246.1 mm
DELUXE 12PK						

