



# Circline

## FC16T9/COOL WHITE PLUS

T9 4-Pin Circular Fluorescent Lamps.


### Product data

General Information	
Cap-Base	G10q
Life to 50% Failures (Nom)	13,000 hour(s)
Light Technical	
Color Code	33
Luminous Flux	2,500 lm
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4100 K
Color rendering index (CRI)	62
Operating and Electrical	
Power Consumption	39.5 W
Lamp Current (Nom)	0.42 A
Voltage (Nom)	109 V
Voltage (Nom)	109 V
Controls and Dimming	
Dimmable	No

Mechanical and Housing	
Bulb Shape	C-T29
Approval and Application	
Mercury (Hg) Content (Nom)	8.0 mg
Product Data	
Order product name	FC16T9/COOL WHITE PLUS
Full product name	FC16T9/COOL WHITE PLUS
Order code	928028803335
Material Nr. (12NC)	928028803335
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677391188
Numerator - Packs per outer box	12
EAN/UPC - Case	50046677391183

# Circline

## Dimensional drawing

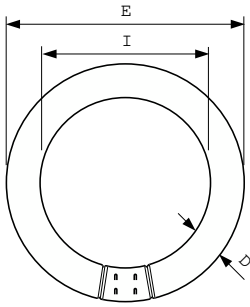

Product	D (max)	D (min)	E (min)	E (max)	I (min)	I (max)
FC16T9/COOL WHITE PLUS	30.9 mm	27.1 mm	393.7 mm	406.4 mm	341.0 mm	347.7 mm

