


Eaton AH1257BK-F

Catalog Number: AH1257BK-F

Recp Sgl Flush 30A 125/250V 3P4W Str BK: AH1257BK-F

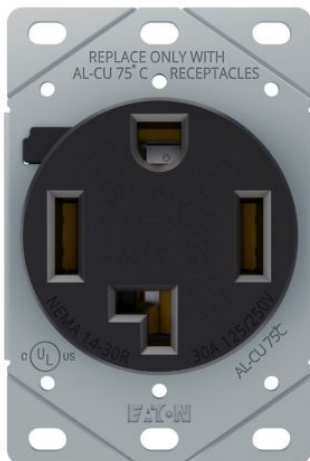

General specifications

Product Name	Catalog Number
Eaton Arrow Hart power device receptacle	AH1257BK-F
	UPC
	032664006364
Product Length/Depth	Product Height
2.112 in	3.688 in
Product Width	Product Weight
2.455 in	0.35 lb

Warranty

Refer to warranty document.

defaultTaxonomyAttributeLabel

Features

Dryer receptacle

Special features

Dryer receptacle

Type

Flush mount receptacle

Amperage Rating

30A

Voltage rating

125/250V

Wiring method

Back

Number of wires

4

Mounting method

Flush

Number Of Poles

Three-pole

Color

Black

Connection type

Screw

Style

Power

NEMA configuration

14-30R

Base color

Black

Design type

Receptacle

Receptacle type

Three-pole, four-wire, grounding

Resources

Brochures

[Flush mount receptacles sell sheet](#)

Specifications and datasheets

[FMR NEMA 14-30, 14-50 spec sheet](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)