


circular conduc. terminal TA7.2 4 x 600...750 kcmil for 4 cables; 1 unit accessory for: circuit breaker, 3-pole 3VA58; 3VA68

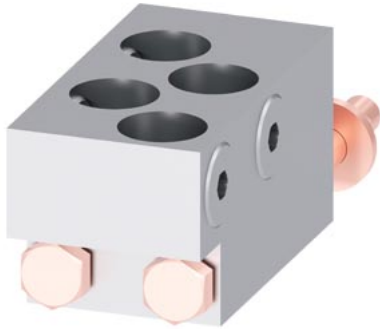

Model	
product brand name	SETRON
accessories	Wire connector
General technical data	
designation / of the terminal	TA7.2
type of electrical connection / with control wire tap	No
Connections according UL	
permissible temperature / of connectable conductor / according to UL 486A-486B	75 °C
stripped length	1.2 in
connectable conductor cross-section	
<ul style="list-style-type: none"> for copper cable / stranded / minimum for copper cable / stranded / maximum for aluminum cable / stranded / minimum for aluminum cable / stranded / maximum 	<ul style="list-style-type: none"> 600 kcmil 750 kcmil 600 kcmil 750 kcmil
tightening torque / when using copper cables	
<ul style="list-style-type: none"> stranded 	600-750 kcmil: 480 lb-in

Certificates		
General Product Approval	Test Certificates	Marine / Shipping



EG-Konf.



[Miscellaneous](#)



[Type Test Certificates/Test Report](#)



LRS

other	Environment
-------	-------------

[Confirmation](#)

[Miscellaneous](#)

[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mifb=3VA9771-0JJ44>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9771-0JJ44>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9771-0JJ44

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

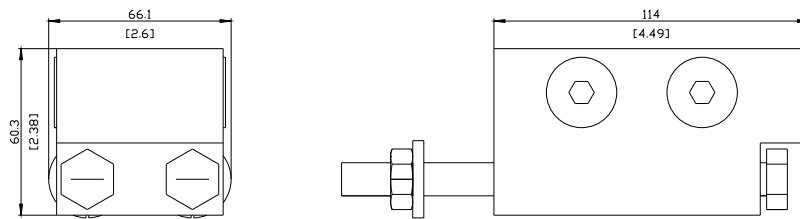

last modified:

1/14/2024 

