



# OD-5-1000L-5CCT

## Wall Sconce LED Light 5CCT 15W

Project: \_\_\_\_\_

Location: \_\_\_\_\_

Model: \_\_\_\_\_ Qty: \_\_\_\_\_

Notes: \_\_\_\_\_


### DESCRIPTION

Wall Sconce 2 or 1 side LED Light 5CCT  
Low Profile with elegant and modern design

### FEATURES & BENEFITS

Wet Location Approved - Suitable For Indoor & Outdoor Installations  
5CCT user selectable 2700K to 5000K  
CRI 90+ for True Color Rendering  
Options of Upward & Downward or Dawnward Light Only  
Durable Aluminum Alloy Body with Glass Diffuser  
Triac Dimmable


**DIMENSIONS**    4 3/4" Square    Thickness 1 3/8"

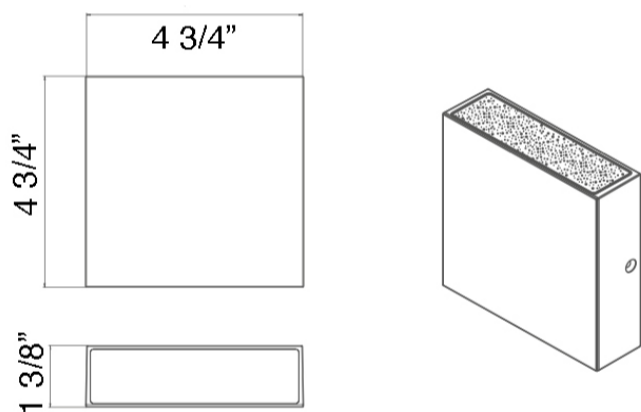

SPECIFICATION	
Applications	Residential, Commercial, Hospitality, Indoor & Outdoor
Power	15 W
Color Temperature (K)	2700 - 3000 - 3500 - 4000 - 5000
Light Output Up & Down each way (lm)	570 - 600 - 630 - 640 - 610
Light Output Up & Down total (lm)	1140 - 1200 - 1260 - 1280 - 1220
Light Output One Side Only total (lm)	1160 - 1100 - 1160 - 1170 - 1130
Halogen Equivalent	100 W
Beam Angle	85°
CRI	90 +
Driver Input	120V-277V AC 50/60 Hz
Dimming	TRIAC Dimmers 10% - 100%
Approved Location	Wet Locations
Ambient Temperature	-4°F (-20°C) to +104°F (+40°C)
Projected Life	70% Light Output at 50,000 Hours
Certification	cETLus
Warranty	5 Year



### INSTALLATION

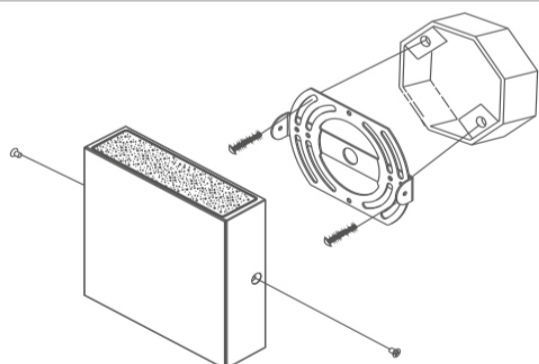

### ORDERING GUIDE

	Light Direction	Trim
<b>OD-5-1000L-5CCT-WH</b>	Up & Down	<a href="#">White</a>
<b>OD-5-1000L-5CCT-BK</b>	Up & Down	<a href="#">Black</a>
<b>OD-5-1000L-5CCT-1S-WH</b>	One Side Only	<a href="#">White</a>
<b>OD-5-1000L-5CCT-1S-BK</b>	One Side Only	<a href="#">Black</a>

5CCT is 2700-3000-3500-4000-5000K user selectable  
Other Finishes Available by Custom Order



### Lotus LED Lights USA

250 H Street # 301, Blaine WA 98230 tel 360-200-5500  
Hainesport NJ, Naples FL, Vancouver WA

[www.LotusLEDLights.com](http://www.LotusLEDLights.com)

mailing addresses  
warehouses

### Lotus LED Lights CANADA

702 Chester Rd, Delta BC V3M 6J1 tel 604-538-3090  
Delta BC, Mississauga ON