



IP53-304610

Project:	Type:	QTY:
Product Code:		



Product Code

IP53 - 304610 - COLOR - INTENSITY - VOLTAGE
W*=White **WW30*=1200+ lm** **120=120V**

Note: * Fully assembled, ready to ship

Features + Specifications

Intended Use:

- Building interior, protected exterior
- 11" diameter body mounts over ceiling box
- Great for closets, utility rooms & stairwells

Construction:

- Spun metal one piece base
- Full size PMMA injection molded low profile drum lens
- Lens twist lock onto base for tight fit

Finish:

- Power coat painted low gloss white

Optical System:

- Good quality multiple 2835 SMDs PCB design, **15W**
- **WW30***=3000K CCT, 1200+ lumens with 80+CRI
- 50000 hrs life rating
- Laminated aluminum PCB for effective heat management
- PMMA frosted opal lens with 140° symmetrical light distribution

Specifications subject to change without notice



Certified to CSA C22.2 No.250.0 Conformed to UL 1598 | Certification marks (where applicable) will be found on our luminaires and its components

iplighting.com



IP53-304610

Custom Lighting Design & Manufacture



Electrical System:

- HPF 90+, high efficiency driver on board design
- Short circuit + Overheat protected
- 120V AC line voltage dimmable
- RoHS compliant

Mounting:

- Mounts directly to standard 4" outlet box

Dimension:

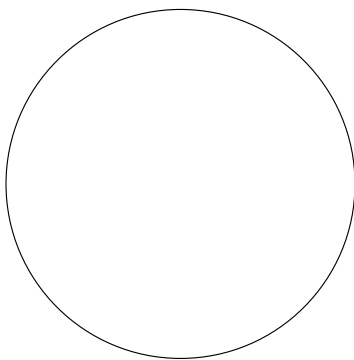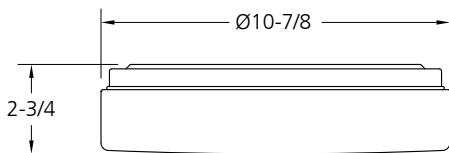

Datecode 20210619

Specifications subject to change without notice