 


Excel

LED panel lights are more accessible than ever before. The sleek and minimal construction allows for the easiest of installations.

UPGRADE



Model	Size	Watts	Delivered lumens	CRI	Color °T	Standard voltage	Multi-voltage ⚡
5003-CC	3"	8 W	600 lm	90	2700, 3000, 3500, 4000, 5000 K	120V, Triac dimming	MV: 120 / 277 / 347V, 0-10V dimming
5004-CC	4"	11 W	800 lm				
5005-CC	5"	12 W	900 lm				
5006-CC	6"	14 W	1100 lm				
5004SQ-CC*	4"	11 W	800 lm				

*Square model

Specifications

Every fixture includes a junction box with an integrated driver
 Over 50,000 hours of service life
 Can be daisy chained
 Minimal heat emission
 Edge lit technology
 Cast aluminum construction
 Switch-selectable CCT: 2700 K/3000 K/3500 K/4000 K/5000 K
 Very low profile
 IC certification (suitable for direct contact with insulation)
 Air-tight certified as per ASTM E283-04
 Suitable for wet locations
 Ideal operating temperature: -20° to 40° C
 Refer to website for dimmer compatibility
 5-year warranty

Finish

- **BK** Black
- **SN** Satin Nickel (5004-CC only)
- **WH** White

Multi-voltage ⚡

This product family offers multi-voltage drivers (120/277/347) that are dimmable using 0-10V dimming systems. Please note that longer lead times may apply for this option. Kindly reach out to your DALI representative for additional information and to confirm availability.


Note

Other color temperatures, finishes, and voltage options are available but may require minimum order quantities (MOQs) and longer lead times. Please contact your DALI representative for more information.


Accessories

- REC-TRIM4-BK (5004)**
4" recessed panel trim in black
- REC-TRIM4-GD (5004)**
4" recessed panel trim in gold
- REC-TRIM4-SN (5004)**
4" recessed panel trim in satin nickel
- REC-TRIM6-BK (5006)**
6" recessed panel trim in black
- REC-TRIM6-GD (5006)**
6" recessed panel trim in gold
- REC-TRIM6-SN (5006)**
6" recessed panel trim in satin nickel
- 5000-EXT8FT**
8-foot extension cable
- 5000-EXT20FT**
20-foot extension cable
- RFP-23 (5003)**
Rough-in plate
- RFP-46 (5004, 5006)**
Rough-in plate
- RFP-58 (5005)**
Rough-in plate
- RFP-UNI (5003, 5004, 5006)**
Universal rough-in plate


5003-CC

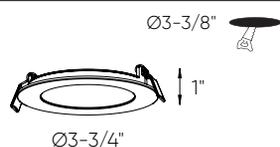


5004-CC

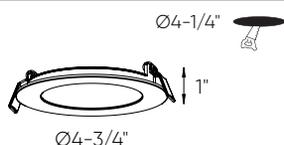


5004SQ-CC

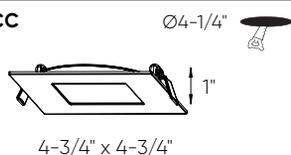

5005-CC

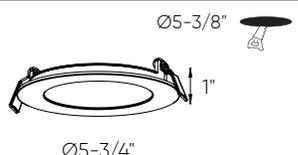

5006-CC

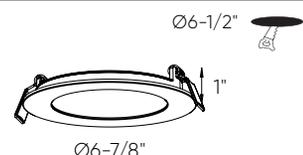

4-1/8" x 2-1/2"
x 1-3/8"

4-1/8" x 2-1/2"
x 1-3/8"

5" x 2-13/16"
x 1-7/16"